



 
WSP 80 / WP 80

Approved heating technology with effective heat transfer.
For all purpose industrial applications. A wide range of soldering
tips are available.




- For universal applications
- Effective heat transfer
- Extensive range of soldering tips
- High quality heater core
- Soldering tip with low material use and therefore lower cost

Knife



Type	Ø a mm
LT KN	2,0
LT KNSL 45°	2,0

Chisel

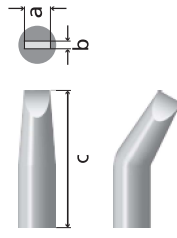

LT				Ø a mm	b mm	c mm	Order-no.
LT 1SC		0,4	0,15	15,0			T005 44 494 99 T005 44 494 10
LT 1SCNW*		0,3	0,1	15,0			T005 44 497 99
LT A		1,6	0,7	12,5			T005 44 440 99 T005 44 440 10 T005 44 403 11
LT ASL		1,6	0,45	12,5			T005 44 516 99 T005 44 516 11
LT B		2,4	0,8	12,5			T005 44 405 99 T005 44 405 10 T005 44 405 11
LT BSL		2,4	0,45	12,5			T005 44 517 99 T005 44 517 11
LT H		0,8	0,4	12,5			T005 44 437 99 T005 44 437 10 T005 44 412 11
LT HSL		0,8	0,4	12,5			T005 44 518 99 T005 44 518 11
LT C		3,2	0,8	12,5			T005 44 407 99 T005 44 407 10 T005 44 407 11
LT D		4,6	0,8	12,5			T005 44 409 99 T005 44 409 10 T005 44 409 11

Type	Ø a mm	b mm	c mm	Order-no.
LT DLL	4,6	1,2	12,5	T005 44 448 99 T005 44 448 10
LT K	1,2	0,4	20,0	T005 44 438 99 T005 44 438 10 T005 44 413 11
LT L	2,0	1,0	20,0	T005 44 414 99 T005 44 414 10 T005 44 414 11
LT M	3,2	1,2	20,0	T005 44 415 99 T005 44 415 10 T005 44 415 11
LT HX 30°	0,8	0,4	17,5	T005 44 420 99 T005 44 420 11
LT ALX 30°	1,6	0,7	17,5	T005 44 443 99 T005 44 443 10
LT BX 30°	2,4	0,8	17,5	T005 44 442 99 T005 44 442 10
LT AX 30°	1,6	0,8	14,1	T005 44 427 99 T005 44 427 10
LT 4X 30°	1,2	0,4	17,2	T005 44 428 99 T005 44 428 10
LT MX 30°	3,2	1,2	20,0	T005 44 469 99

Round



Type	Ø a mm	c mm	Order-no.
LT 1S	0,2	15,0	T005 44 436 99 T005 44 402 10
LT 1SNW*	0,1	15,0	T005 44 496 99

Conical



Type	Ø a mm
LT 1L	0,2
LT 1LNW*	0,1
LT S	0,4

Gull Wing



Type	Ø a mm	b mm
LT GW1	2,3	3