


SMR/F211, Film, Metallized PPS, General Purpose, 0.15 uF, 10%, 100 VDC, 125C, Lead Spacing = 5mm

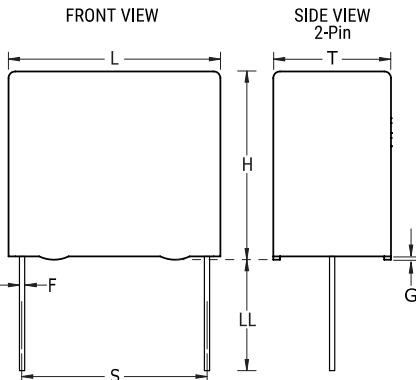

General Information	
Supplier:	KEMET
Series:	SMR/F211
Dielectric:	Metallized PPS
Style:	Radial
Features:	Audio Applications
RoHS:	Yes
Lead:	Wire Leads
Miscellaneous:	The rated voltage decreases 2%/C between +125C and +150C
Notes:	Case Size = JT

Dimensions	
L	7.2mm MAX
H	11mm MAX
T	6mm MAX
S	5mm +/-0.4mm
LL	4mm +1mm
F	0.5mm +/-0.05mm
G	0.5mm NOM

Packaging Specifications	
Packaging:	Bulk, Tray
Packaging Quantity:	1000

Specifications	
Capacitance:	0.15 uF
Capacitance Tolerance:	10%
Voltage AC:	63 VAC
Voltage DC:	100 VDC
Temperature Range:	-55/+150C
Rated Temperature:	125C
Dissipation Factor:	0.15% 1kHz, 0.25% 10kHz
Insulation Resistance:	15 GOhms
Max dV/dt:	15 V/us

Statements of suitability for certain applications are based on our knowledge of typical operating conditions for such applications, but are not intended to constitute - and we specifically disclaim - any warranty concerning suitability for a specific customer application or use. This Information is intended for use only by customers who have the requisite experience and capability to determine the correct products for their application. Any technical advice inferred from this Information or otherwise provided by us with reference to the use of our products is given gratis, and we assume no obligation or liability for the advice given or results obtained.