


KEMET, TPI, Power, 180 nH, 10%

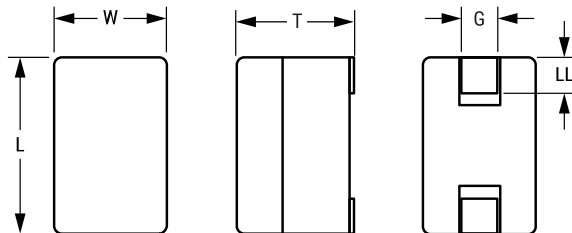

Dimensions

Chip Size	4731
L	12mm MAX
W	8mm MAX
T	8mm MAX
LL	2.2mm NOM
G	2.3mm +/-0.1mm

Packaging Specifications

Packaging:	T&R, 330mm
Packaging Quantity:	400

General Information

Series:	TPI
Style:	SMD Chip
Description:	Surface Mount Inductor
Features:	Power Inductors
RoHS:	Yes
Core:	Ferrite
Miscellaneous:	40 (K) Temperature Rise Max.

Specifications

Inductance:	180 nH (0.1 MHz)
Inductance Tolerance:	10%
Temperature Range:	-40/+125C
Shielded:	Yes
Current:	78 A (Isat, 20% Drop In Inductance), 50 A (Irms, 40C Rise By Self Heating)