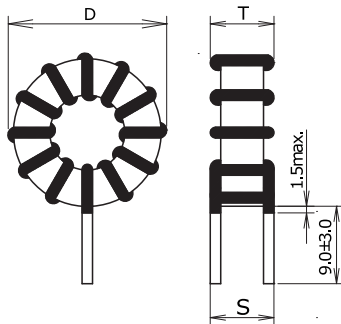


KEMET, PHBC, Choke, 54 uH, 20%

**General Information**

Series:	PHBC
Style:	Through-Hole Toroid
Description:	Normal Mode Choke Coil. AC Line Filter.
Features:	Switching Power Supply Outlet, DC-DC Converter, Phase Compensation, Noise Solution
RoHS:	Yes
Lead:	Wire Leads
Core:	Ferrite
Miscellaneous:	35 (K) Temperature Rise Max.

Dimensions

D	41.2mm MAX
T	19.5mm MAX
S	14mm NOM
LL	9mm +/-3mm
G	1.5mm MAX
Wire Size	1.7mm

Specifications

Inductance:	54 uH (0.1 MHz)
Inductance Tolerance:	20%
Temperature Range:	-40/+125C
Rated Temperature:	125C
Current:	12 A (MAX)

Packaging Specifications

Weight:	66 g
Packaging:	Tray
Packaging Quantity:	80