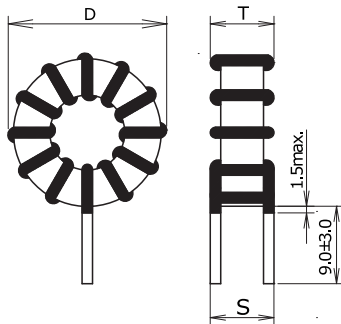


KEMET, PHBC, Choke, 219 uH, 20%

**General Information**

Series:	PHBC
Style:	Through-Hole Toroid
Description:	Normal Mode Choke Coil. AC Line Filter.
Features:	Switching Power Supply Outlet, DC-DC Converter, Phase Compensation, Noise Solution
RoHS:	Yes
Lead:	Wire Leads
Core:	Ferrite
Miscellaneous:	65 (K) Temperature Rise Max.

Dimensions

D	50.5mm MAX
T	26.5mm MAX
S	19mm NOM
LL	9mm +/-3mm
G	1.5mm MAX
Wire Size	2mm

Specifications

Inductance:	219 uH (0.1 MHz)
Inductance Tolerance:	20%
Temperature Range:	-40/+125C
Rated Temperature:	125C
Current:	15 A (MAX)

Packaging Specifications

Weight:	149 g
Packaging:	Tray
Packaging Quantity:	60