


KEMET, ESD-R-H, EMI Cores, Commercial Grade

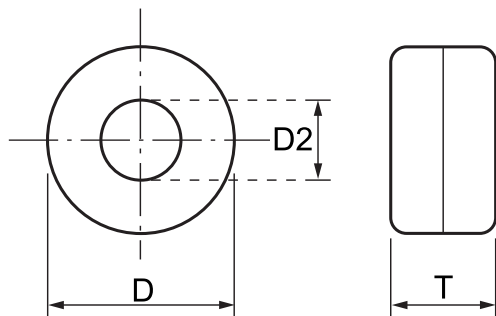

General Information	
Series:	ESD-R-H
Style:	Split-Core
Cable Type:	Round Cable
Description:	EMI Core Solid, For Round Cables, Toroidal Cores
Features:	High Heat Resistance, Cable Holding Mechanism
RoHS:	Yes
Qualifications:	UL94V-0
Case Color:	White
Materials:	Mn-Zn

Dimensions	
D	15mm MAX
D2	5mm +/-1.0mm
T	9mm MAX

Specifications	
Temperature Range:	-40/+120C
Effective Frequency:	10 MHz (AM Band Range)

Packaging Specifications	
Packaging:	Tray
Packaging Quantity:	2000
Weight:	2.6 g

Statements of suitability for certain applications are based on our knowledge of typical operating conditions for such applications, but are not intended to constitute - and we specifically disclaim - any warranty concerning suitability for a specific customer application or use. This Information is intended for use only by customers who have the requisite experience and capability to determine the correct products for their application. Any technical advice inferred from this Information or otherwise provided by us with reference to the use of our products is given gratis, and we assume no obligation or liability for the advice given or results obtained.