



# PLVW92U - PLVW125U - PLVW154U - PLVW194U

PyleUSA.com Video Monitor Panel Display Screen, Full HD 1080p Support, HDMI/RCA/VGA Connectors

The Pyle 'PLVW' LCD Monitor Display Screens are universal and can be used in a wide variety of applications. Mount the versatile video display in your vehicle, at home or in the office. They are perfect for custom installations and can be used for convenient safety surveillance monitoring, vehicle media entertainment, as an optional second monitor expansion and more. The slim-styled panel design allows for simple HD high-resolution video display ability wherever needed. Connect your system using the inputs: (2) RCA video, (1) HDMI and (1) VGA connector; it also features RCA audio (L/R) connector jacks for connection to an external sound system. Enjoy the convenience of widescreen HD video display with the Pyle 'PLVW' Universal Monitor Systems.


### FRONT PANEL

1. **MODE:** Switch between the video inputs. (HDMI,RCA1,RCA2,VGA)
2. **Analog Decrease:** Forward select setting the items or analog decrease menu.
3. **MENU:** Open the menu to adjust the units display settings.
4. **Analog Increase:** Backward select setting the items or analog increase menu.
5. **POWER:** Turn the unit on and off.
6. **1R:** Remote control receiver.

Please read this manual thoroughly before using this product and keep for future reference.



### REMOTE

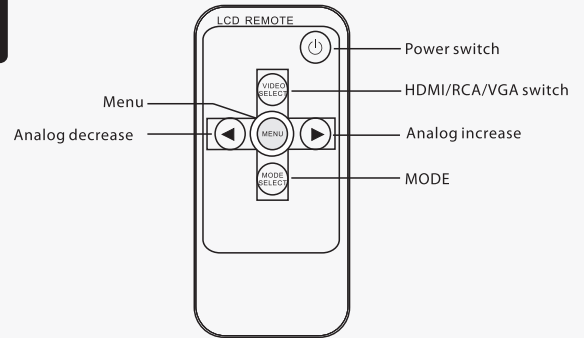

### WIRING



Power supply do not meet the polarity, otherwise It will damage Insurance tube. (Fuse Specifications : 3A or 5A)

VGA Supported Video Modes: Maximum matching resolution

**HDMI Supported Video Modes:**  
1080P/1080I/720P/480P/576P

#### Important Note:

**Video Inputs: RCA/VGA** are used only for video signal input transmission -- do not support audio

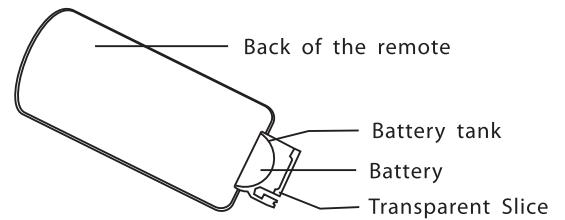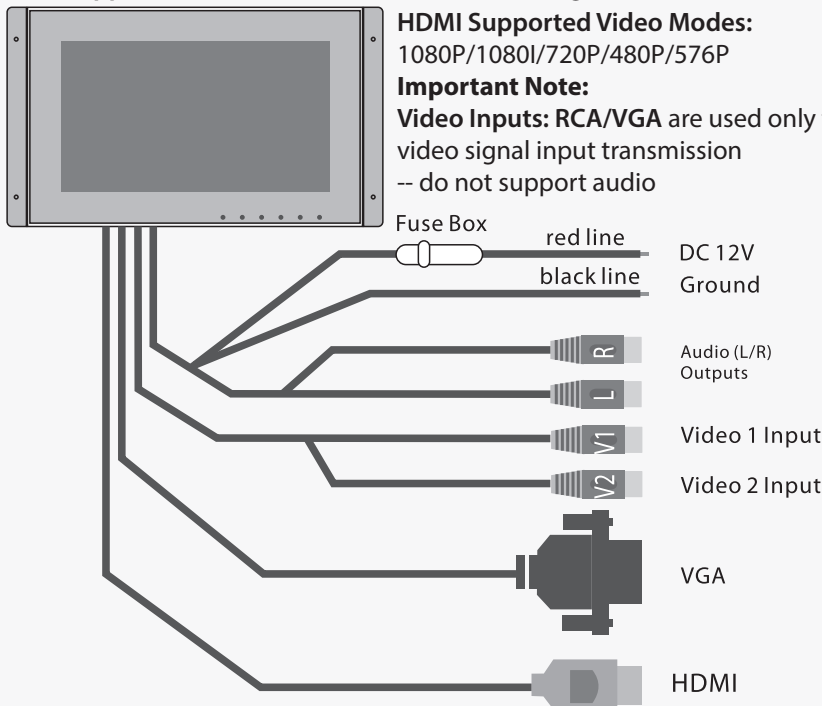

### REMOTE CONTROL BATTERY

1. Always use new batteries when relacing the old set.
2. Do not attempt to charge, short-circuit, disassemble, heat or burn used batteries.
3. Battery replacement is necessary when remote control acts sporadically or stops operating this device.
4. Do not place objects between the remote receiver.
5. If the monitor does not operate even when operating the remote control from a close range, it is time to replace the batteries.

### MENU OPERATION Use the unit to achieve the desired settings.

1. Press the **MENU** button on the unit to bring up the on-screen picture control menu.
2. Select the desired menu by pressing the Remote left/right button on the unit to choose **BRIGHTNESS-CONTRAST-HUE-SATURATION-LANGUAGE SOURCE-RESET-EXIT**. Press the Remote **MENU** button to enter into the control menu.
3. Adjust the current settings with the left/right button on the unit, then press the **MENU** button on unit to achieve the desired settings and return to the upper level of the menus.

**Notice:** In different mode menu is slightly different.

## INSTALLATION & MOUNTING

### 1. Drive Mounting Holes


Draw a cutting line on the wall according to the following size to install. The depth of the hole should be larger than 36MM.

SIZE / DIMENSIONS (L X W X D)				
MODEL	PLVW92U	PLVW125U	PLVW154U	PLVW194U
Cut-Out Dimensions	10.3" x 7.2" x 1.5"	14.0" x 9.5" x 1.5"	15.7" x 11.2" x 1.5"	13.4" x 18.5" x 1.5"
TOTAL DIMENSIONS				
-with Frame	12.2" x 7.9" x 1.1"	16.0" x 10.0" x 1.1"	17.6" x 11.8" x 1.1"	20.4" x 13.9" x 1.3"
-without Frame	11.4" x 6.7" x 0.9"	15.1" x 8.9" x 0.9"	16.8" x 10.6" x 0.9"	19.6" x 12.8" x 1.1"
Weight	4.25 lbs.	6.05 lbs.	7.86 lbs.	11.67 lbs.

### 2. Install the Main

Connect the lines, place the subjects in mounting hole, upper and lower case-preserving Gap, then with 4 screws.


**Screw Specifications:** 4mm X 12mm or 4mm X (12+\*)mm

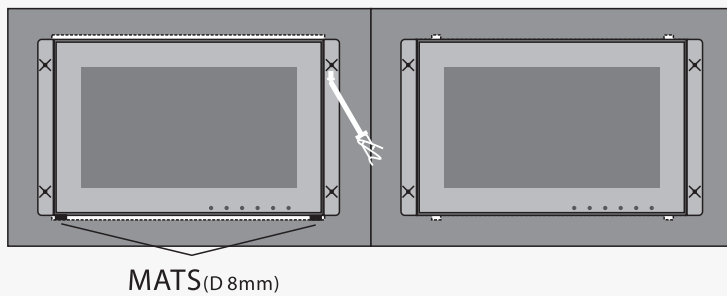

### 3. Panel Mounting


The display area is aligned with the position of the panel in the frame body, a little hard press to hang buckle at the surface of the panel and the body fit.

**Note:** The frame display area must be entirely within the neat, buckle clasp firmly to hang.

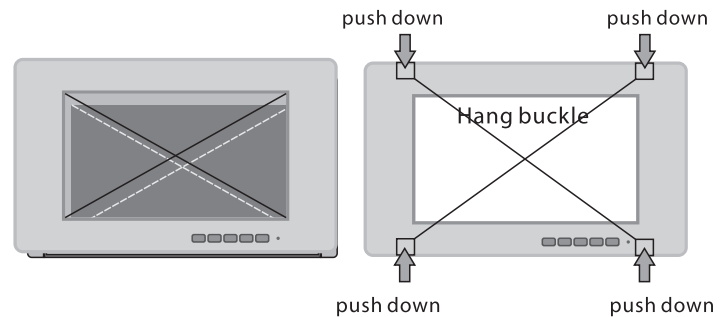

### 4. Panel Removal

Use a screwdriver or other flat tool, slightly hard to pry the bottom right corner (part 1), bottom right hang buckle will depart from the main body of the Panel; Then use the same method to open the panels hang buckle 2,3,4, to remove the Panel.

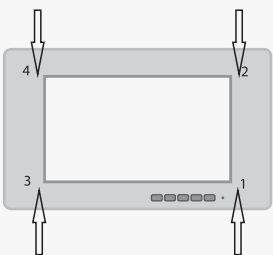

MODEL	PLVW92U	PLVW125U	PLVW154U	PLVW194U
Video Display Screen Size	9.0" -inch	12.5" -inch	15.4" -inch	19.0" -inch
Native Resolution	800 x 480 (RGB)	1366 x 768 (RGB)	1280 x 800 (RGB)	1440 x 900 (RGB)
Contrast Ratio	500:1	500:1	500:1	1000:1
Brightness	200 cd/m	250cd/m	250cd/m	250cd/m
Power Consumption	<5.5 Watt	<6.5 Watt	<11.5 Watt	<18 Watt
Amperage Draw	3A	3A	3A	3A

### FEATURES:

- Full HD 1080p Support
- Widescreen HD LCD Display
- In-Wall / In-Console Mountable
- For Vehicle & Home/Office Applications
- Universal Mount Perfect for Custom Installations
- Removable Screen Display Frame
- HDMI, VGA, (2) x RCA Video Input Connectors
- RCA (L/R) Audio Output Connector Jacks
- Video Input Selectable
- Front Panel Button Controls

- Steel Monitor Housing Frame Cut-Out Holes for Easy Mounting
- Brightness, Contrast, Hue, Saturation Adjustable
- Stain Resistant & Paintable Monitor Frame
- Works Great as Surveillance Display
- Includes Wireless Remote Control, Cut-Out Template, Mounting Screws
- \*Power Supply Cable Available, Model Sold Separately: PS5A

### TECHNICAL SPECS:

- **HDMI Support:** 1080p, 1080i, 720p, 480p, 576p
- **PAL/NTSC Auto Color System**
- **Screen Aspect Ratio Selectable** - 16:9 / 4:3
- **Power Supply:** DC 12V



### VISIT US ONLINE:

Have a question?  
Need service or repair?  
Want to leave a comment?

[PyleUSA.com/ContactUs](http://PyleUSA.com/ContactUs)

# PYLE