

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1727080022

Status:


Active

Overview:

Mini-Fit Jr. Power Connectors

Description:

Mini-Fit TPA2 Receptacle Housing, 4.20mm Pitch, Dual Row, UL 94V-0, Low-Halogen, 22 Circuits

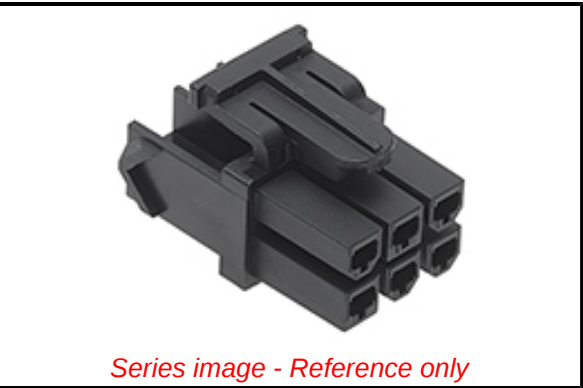

Documents:

Drawing (PDF)

Product Specification 2029880001-PS-000 (PDF)

Application Specification AS-172718-0000-001 (PDF)

Packaging Specification 1727080001-PK-000 (PDF)

Test Summary 2029880001-TS-000 (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Crimp Housings
Series	172708
Application	Power, Wire-to-Board, Wire-to-Wire
Comments	See product specification for current derating information.
Overview	Mini-Fit Jr. Power Connectors
Product Name	Mini-Fit TPA2
UPC	191128361491
Physical	
Circuits (maximum)	22
Color - Resin	Black
Gender	Receptacle
Glow-Wire Capable	No
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	3.861/g
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	4.20mm
Pitch - Termination Interface	4.20mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C
Material Info	
Reference - Drawing Numbers	
Application Specification	AS-172718-0000-001
Packaging Specification	1727080001-PK-000
Product Specification	2029880001-PS-000
Sales Drawing	SD-172708-0000-000
Test Summary	2029880001-TS-000

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -

ED/61/2018 (27 June

2018)

Halogen-Free

Status

Low-Halogen

For more information, please visit

Contact US

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

172708 Series

Mates With

Mini-Fit TPA2 Plug Housing 172762 ,

172767
Mini-Fit Jr. Plug Housing 5559

Mini-Fit Jr. Headers 5566 , 5569

Use With

Mini-Fit TPA2 Female Terminal 172718 ,

202988
Mini-Fit TPA2 Retainer 172709

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION