

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1703520002](#)  
**Status:** **Active**  
**Description:** EXTreme Guardian 2 Circuit TPA

**Documents:**

[3D Model](#) [Product Specification PS-46819-001-001 \(PDF\)](#)  
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family Crimp Housings  
 Series [170352](#)  
 Application Wire-to-Board, Wire-to-Wire  
 Product Name EXTreme Guardian  
 UPC 884982274457


**Physical**

Circuits (maximum) 0  
 Color - Resin Black  
 Gender N/A  
 Glow-Wire Capable No  
 Keying to Mating Part None  
 Material - Resin Polyester  
 Net Weight 1.750/g  
 Number of Rows 1  
 Packaging Type Bag  
 Panel Mount N/A  
 Pitch - Mating Interface N/A  
 Temperature Range - Operating -40° to +105°C

**Material Info**

**Reference - Drawing Numbers**

Product Specification PS-46819-001-001  
 Sales Drawing SD-170352-0002

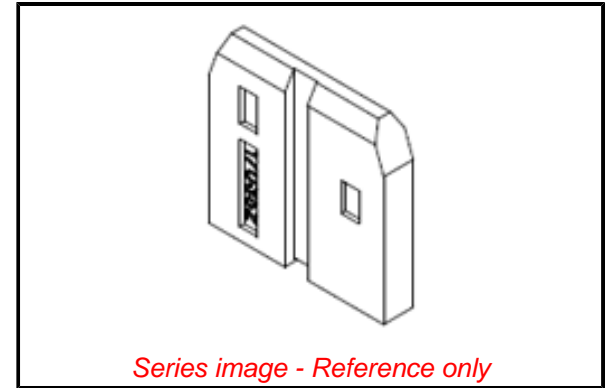

**EU ELV**

**Compliant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
 ED/61/2018 (27 June  
 2018)

**Halogen-Free**

**Status**

**Not Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Compliant

Not Contained

**Search Parts in this Series**

[170352](#) Series

**Use With**

[170351](#) EXTreme Guardian Crimp Harness  
 Housing