

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0191440001](#)
Status: **Active**
Overview: [Solderless Terminals](#)
Description: InsulKrimp Spade Tongue Terminal for 18-22 AWG Wire

Documents:
[Drawing \(PDF\)](#) [Product Specification PS-19902-011-001 \(PDF\)](#)
[Product Specification 194130104-000 \(PDF\)](#) [Product Specification PS-19902-013-001 \(PDF\)](#)
[Product Specification PS-19902-009-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification
CSA LR18689
UL E32244


General
Product Family Ring and Spade Terminals
Series [19144](#)
Crimp Quality Equipment Yes
Mil-Spec N/A
Overview [Solderless Terminals](#)
Product Name InsulKrimp
Type Spade
UPC 800753104570

Physical
Barrel Type Closed
Color - Resin Natural
Flammability 94V-0
Insulation PVC
Material - Plating Mating Tin
Net Weight 0.733/g
Packaging Type Bag
Stud Size 5-6 (M3-3.5)
Termination Interface: Style Crimp or Compression
Wire Insulation Diameter 3.70mm max.
Wire Size AWG 18, 20, 22
Wire Size mm² 0.35-0.80

Solder Process Data
Lead-freeProcess Capability N/A

Material Info
Engineering Number AA-235-06X

Reference - Drawing Numbers
Product Specification 194130104-000, PS-19902-009-001,
PS-19902-011-001, PS-19902-013-001
Sales Drawing AACD20303

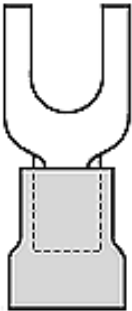

Series image - Reference only

EU ELV
Not Relevant

EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per	
-ED/01/2018 (15	
January 2018)	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[19144 Series](#)