

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0191640040**
Status: **Active**
Overview: Snap Plugs and Receptacles
Description: Perma-Seal Male Snap Plug for 14-16 AWG Wire, Diameter 3.96mm

Documents:

Drawing (PDF)	Product Specification PS-19902-013-001 (PDF)
Product Specification PS-19902-011-001 (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification

CSA	LR18689
UL	E152602

General

Product Family	Quick Disconnects
Series	<u>19164</u>
Crimp Quality Equipment	Yes
Insulated	Partial
Overview	<u>Snap Plugs and Receptacles</u>
Product Name	Perma-Seal
Type	Snap Plug
UPC	800753113251

Physical

Barrel Type	Closed
Color - Resin	Blue
Gender	Male
Glow-Wire Capable	No
Insulation	NiAc
Lock to Mating Part	None
Material - Metal	Copper
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	1.343/g
Orientation	Straight
Packaging Type	Bag
Tab Thickness	N/A
Tab Width	N/A
Temperature Range - Operating	-55° to +125°C
Wire Insulation Diameter	6.71mm max.
Wire Size AWG	14, 16
Wire Size mm ²	1.00-2.50

Electrical


Voltage - Maximum	600V
-------------------	------

Material Info

Engineering Number	SB-289
--------------------	--------

Reference - Drawing Numbers

Product Specification	PS-19902-011-001, PS-19902-013-001
Sales Drawing	SD-19164-031

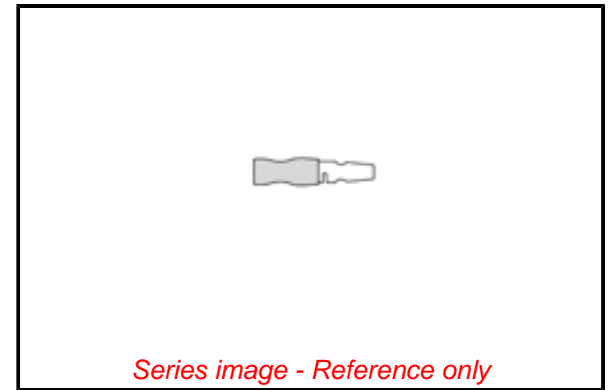

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/61/2018 (27 June
2018)

Halogen-Free

Status

Low-Halogen

**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
Prop65	Compliant
RoHS Phthalates	Not Contained

Search Parts in this Series

19164 Series