

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0191640047
Status: Active
Overview: Perma-Seal Terminals
Description: Perma-Seal Female Quick Disconnect for 14-16 AWG Wire, Tab Size 6.35 x 0.81mm

Documents:
[Drawing \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#)
[Product Specification PS-19902-013-001 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)


General
Product Family Quick Disconnects
Series 19164
Crimp Quality Equipment Yes
Insulated Partial
Overview Perma-Seal Terminals
Product Name Perma-Seal
Type Quick Disconnect
UPC 800753113329

Physical
Barrel Type Closed
Color - Resin Blue
Gender Female
Glow-Wire Capable No
Insulation NiAc
Lock to Mating Part None
Material - Metal Brass
Material - Plating Mating Tin
Material - Plating Termination Tin
Net Weight 1.024/g
Orientation Straight
Packaging Type Bag
Tab Thickness 0.81mm
Tab Width 6.35mm
Temperature Range - Operating -55° to +125°C
Wire Insulation Diameter 5.97mm max.
Wire Size AWG 14, 16
Wire Size mm² 1.00-2.50

Electrical
Voltage - Maximum 600V

Material Info
Engineering Number SBB-2141

Reference - Drawing Numbers
Product Specification PS-19902-011-001, PS-19902-013-001
Sales Drawing SD-19164-040

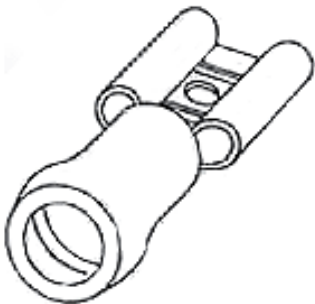

Series image - Reference only

EU ELV
Not Relevant

EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - ED/61/2018 (27 June 2018)	
Halogen-Free	
Status	
Low-Halogen	
Need more information on product environmental compliance?	
Email productcompliance@molex.com	
Please visit the Contact Us section for any non-product compliance questions.	
China ROHS	Not Relevant
ELV	Not Relevant
Prop65	Compliant
RoHS Phthalates	Not Contained

Search Parts in this Series
19164 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION