


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0191640061](#)
Status: **Active**
Overview: [Perma-Seal Terminals](#)
Description: Perma-Seal Ring Tongue Terminal for 10-12 AWG Wire, Stud Size 6 (M3.5)

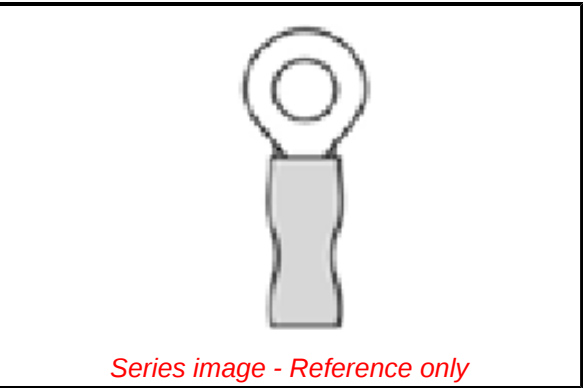

Documents:
[3D Model](#) [Product Specification PS-19902-013-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#)

Agency Certification
CSA LR18689
UL E32244

General
Product Family Ring and Spade Terminals
Series [19164](#)
Crimp Quality Equipment Yes
Mil-Spec N/A
Overview [Perma-Seal Terminals](#)
Product Name Perma-Seal
Type Ring
UPC 800753113466

Physical
Barrel Type Closed
Insulation NiAc
Material - Plating Mating Tin
Net Weight 2.042/g
Packaging Type Bag
Plating min - Mating 2.540µm
Plating min - Termination 2.540µm
Stud Size 6 (M3.5)
Wire Insulation Diameter 7.87mm
Wire Size AWG 10, 12
Wire Size mm² 3.09-5.01

Material Info
Engineering Number SC-228-06

Reference - Drawing Numbers
Product Specification PS-19902-011-001, PS-19902-013-001
Sales Drawing SD-19164-041

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
ED/61/2018 (27 June
2018)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[19164 Series](#)