

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** **0191640075**  
**Status:** **Active**  
**Overview:** Perma-Seal Terminals  
**Description:** Perma-Seal Male Quick Disconnect Tab for 10-12 AWG Wire, Tab Size 6.35 x 0.81mm

**Documents:**

<a href="#">Drawing (PDF)</a>	<a href="#">Product Specification PS-19902-013-001 (PDF)</a>
<a href="#">Product Specification PS-19902-011-001 (PDF)</a>	<a href="#">RoHS Certificate of Compliance (PDF)</a>

**Agency Certification**

CSA	LR18689
UL	E79133

**General**

Product Family	Quick Disconnects
Series	<u>19164</u>
Crimp Quality Equipment	Yes
Insulated	Fully
Overview	<u>Perma-Seal Terminals</u>
Product Name	Perma-Seal
Type	Quick Disconnect
UPC	800753113596

**Physical**

Barrel Type	Closed
Color - Resin	Yellow
Gender	Male
Glow-Wire Capable	No
Insulation	NiAc
Lock to Mating Part	None
Material - Metal	Brass
Material - Plating Mating	Zinc Chromate
Material - Plating Termination	Zinc Chromate
Net Weight	2.830/g
Orientation	Straight
Packaging Type	Bag
Tab Thickness	0.81mm
Tab Width	6.35mm
Temperature Range - Operating	-55° to +125°C
Wire Insulation Diameter	5.84mm max.
Wire Size AWG	10, 12
Wire Size mm <sup>2</sup>	4.00-6.00

**Electrical**


Voltage - Maximum	600V
-------------------	------

**Material Info**

Engineering Number	SC-9280
--------------------	---------

**Reference - Drawing Numbers**

Product Specification	PS-19902-011-001, PS-19902-013-001
Sales Drawing	SD-19164-039

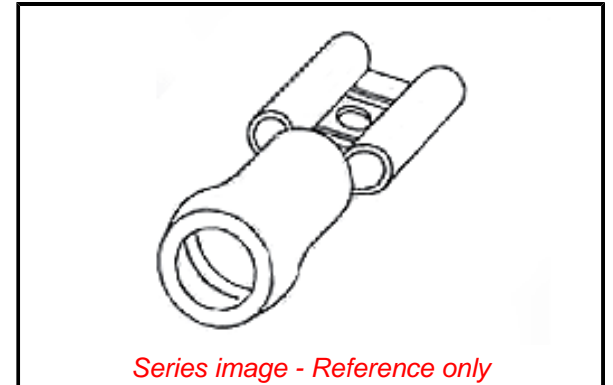

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per - ED/61/2018 (27 June 2018)

**Halogen-Free**

**Status**

**Low-Halogen**

**Need more information on product environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Not Relevant
ELV	Not Relevant
Prop65	Compliant
RoHS Phthalates	Not Contained

**Search Parts in this Series**

19164 Series