

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0191930106
Status: Active
Overview: VersaKrimp Terminals and Splices
Description: VersaKrimp Ring Tongue Terminal for 10-12 AWG Wire

Documents:
[Drawing \(PDF\)](#)
[Product Specification 194130109-000 \(PDF\)](#)
[Product Specification 194130110-000 \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#)
[Product Specification PS-19902-013-001 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR18689
UL E32244

General

Product Family Ring and Spade Terminals
Series 19193
Crimp Quality Equipment Yes
Mil-Spec N/A
Overview VersaKrimp Terminals and Splices
Product Name VersaKrimp
Type Ring
UPC 800755049459

Physical


Barrel Type Closed - Brazed
Insulation None
Material - Plating Mating Tin
Net Weight 1.500/g
Packaging Type Bag
Stud Size 8 (M4)
Wire Size AWG 10, 12
Wire Size mm² 3.30-5.00

Material Info

Engineering Number C-328-08

Reference - Drawing Numbers

Product Specification 194130109-000, 194130110-000, PS-19902-011-001, PS-19902-013-001
Sales Drawing SD-19193-023

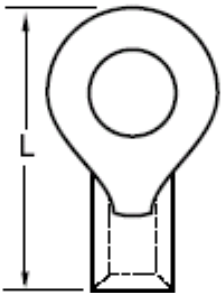

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
ED/61/2018 (27 June
2018)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[19193 Series](#)