

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0191930230
Status: Active
Overview: VersaKrimp Terminals and Splices
Description: VersaKrimp Ring Tongue Terminal for 6 AWG Wire

Documents:
[Drawing \(PDF\)](#) [Product Specification PS-19902-013-001 \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)


Agency Certification
CSA LR18689
UL E32244

General
Product Family Ring and Spade Terminals
Series 19193
Crimp Quality Equipment Yes
Mil-Spec N/A
Overview VersaKrimp Terminals and Splices
Product Name VersaKrimp
Type Ring
UPC 800755050783

Physical
Barrel Type Closed - Brazed
Insulation None
Material - Plating Mating Tin
Net Weight 7.530/g
Packaging Type Bag
Plating min - Mating 2.540µm
Plating min - Termination 2.540µm
Stud Size 3/8" (M9)
Termination Interface: Style Crimp or Compression
Wire Size AWG 6

Material Info
Engineering Number E-358-38

Reference - Drawing Numbers
Product Specification PS-19902-011-001, PS-19902-013-001
Sales Drawing SD-19193-005

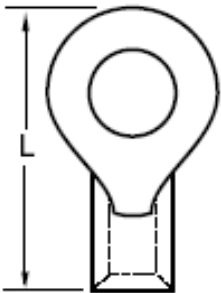

Series image - Reference only

EU ELV
Not Relevant

EU RoHS Compliant REACH SVHC Not Contained Per - ED/61/2018 (27 June 2018) Halogen-Free Status Low-Halogen Need more information on product environmental compliance? Email productcompliance@molex.com Please visit the Contact Us section for any non-product compliance questions.	China RoHS China ROHS Green Image ELV Not Relevant Prop65 Compliant RoHS Phthalates Not Contained
---	--

Search Parts in this Series
[19193](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION