

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0191980019](#)
Status: **Active**
Overview: [Solderless Terminals](#)
Description: Avikrimp Spade Tongue Terminal for 14-16 AWG Wire

Documents:
[3D Model](#) [Product Specification PS-19902-013-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#)


Agency Certification
CSA LR18689
UL E32244

General
Product Family Ring and Spade Terminals
Series [19198](#)
Crimp Quality Equipment Yes
Mil-Spec N/A
Overview [Solderless Terminals](#)
Product Name Avikrimp
Type Spade
UPC 800753046108

Physical
Barrel Type Closed
Flammability 94V-0
Insulation Nylon (PA)
Material - Plating Mating Tin
Net Weight 0.907/g
Packaging Type Bag
Plating min - Mating 2.540µm
Plating min - Termination 2.540µm
Stud Size 8 (M4)
Termination Interface: Style Crimp or Compression
Wire Insulation Diameter 4.30mm max.
Wire Size AWG 14, 16
Wire Size mm² 1.30-2.00

Material Info
Engineering Number BB-824-08

Reference - Drawing Numbers
Product Specification PS-19902-011-001, PS-19902-013-001
Sales Drawing SD-19198-001

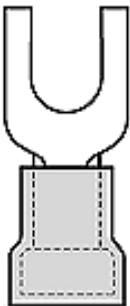

Series image - Reference only

EU ELV
Not Relevant

EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - ED/61/2018 (27 June 2018)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[19198 Series](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION