

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0191980025
Status: Active
Overview: Solderless Terminals
Description: Avikrimp Spade Tongue Terminal for 14-16 AWG Wire

Documents:
3D Model Product Specification PS-19902-013-001 (PDF)
Drawing (PDF) RoHS Certificate of Compliance (PDF)
Product Specification PS-19902-011-001 (PDF)


Agency Certification
CSA LR18689
UL E32244

General
Product Family Ring and Spade Terminals
Series 19198
Crimp Quality Equipment Yes
Mil-Spec N/A
Overview Solderless Terminals
Product Name Avikrimp
Type Spade
UPC 800753046191

Physical
Barrel Type Closed
Flammability 94V-0
Insulation Nylon (PA)
Material - Plating Mating Tin
Net Weight 1.103/g
Packaging Type Bag
Plating min - Mating 2.540µm
Plating min - Termination 2.540µm
Stud Size 10 (M5)
Termination Interface: Style Crimp or Compression
Wire Insulation Diameter 4.30mm max.
Wire Size AWG 14, 16
Wire Size mm² 1.30-2.00

Material Info
Engineering Number BB-827-10

Reference - Drawing Numbers
Product Specification PS-19902-011-001, PS-19902-013-001
Sales Drawing SD-19198-001

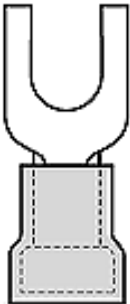

Series image - Reference only

EU ELV
Not Relevant

EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - ED/61/2018 (27 June 2018)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
19198 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION