

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0191980070
Status: Active
Overview: Solderless Terminals
Description: Avikrimp Spade Tongue Terminal for 18-22 AWG Wire

Documents:
[Drawing \(PDF\)](#) [Product Specification PS-19902-013-001 \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)


Agency Certification
CSA LR18689
UL E32244

General
Product Family Ring and Spade Terminals
Series 19198
Crimp Quality Equipment Yes
Mil-Spec N/A
Overview Solderless Terminals
Product Name Avikrimp
Type Spade
UPC 800753046580

Physical
Barrel Type Closed
Flammability 94V-0
Insulation Nylon (PA)
Material - Plating Mating Tin
Net Weight 0.864/g
Packaging Type Bag
Stud Size 5-6 (M3-3.5)
Wire Insulation Diameter 3.60mm max.
Wire Size AWG 18, 20, 22
Wire Size mm² 0.35-0.80

Material Info
Engineering Number AA-835-06

Reference - Drawing Numbers
Product Specification PS-19902-011-001, PS-19902-013-001
Sales Drawing AACD80303

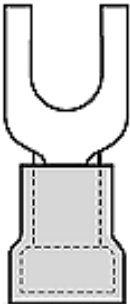

Series image - Reference only

EU ELV
Not Relevant

EU RoHS Compliant REACH SVHC Not Contained Per - ED/61/2018 (27 June 2018) Halogen-Free Status Not Low-Halogen Need more information on product environmental compliance? Email productcompliance@molex.com Please visit the Contact Us section for any non-product compliance questions.	China RoHS China ROHS Green Image ELV Not Relevant Prop65 Compliant RoHS Phthalates Not Contained
---	--

Search Parts in this Series
[19198](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION