

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0194170048](#)
Status: **Active**
Overview: [MX150L Industrial Sealed Connector System](#)
Description: MX150L Male Terminal for 18-22 AWG Wire, Length 25.40mm

Documents:

Drawing (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification PS-19417-001-001 (PDF)	Product Literature (PDF)
Packaging Specification PK-19417-002 (PDF)	

Agency Certification

CSA	LR18689
UL	E152602

General

Product Family	Crimp Terminals
Series	19417
Application	Power, Wire-to-Wire
Comments	UL E152602 Standard Length
Crimp Quality Equipment	Yes
Overview	MX150L Industrial Sealed Connector System
Packaging Alternative	19417-0024 (Reel)
Product Literature Order No	987650-2181
Product Name	MX150L
UPC	822348035748


Physical

Durability (mating cycles max)	25
Gender	Male
Material - Metal	High Performance Alloy (HPA)
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	0.347/g
Packaging Type	Bag
Plating min - Mating	1.905µm
Plating min - Termination	1.905µm
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	2.36-2.74mm
Wire Size AWG	18, 20, 22
Wire Size mm ²	N/A

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-19417-002
Product Specification	PS-19417-001-001
Sales Drawing	SD-19417-001

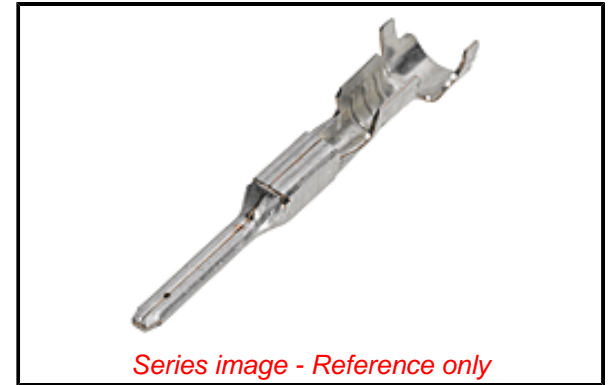

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/61/2018 (27 June
2018)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[19417 Series](#)

Mates With

[19420](#)

Use With

[19419](#) , [19429](#)