

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0196060003](#)
Status: **Active**
Overview: [Standard Quick-Disconnect Terminals](#)
Description: [InsulKrimp Female Quick Disconnect for 10-12 AWG Wire, Mylar Tape](#)

Documents:
[3D Model](#) [Product Specification PS-19902-015-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-19902-008-001 \(PDF\)](#)

Agency Certification

CSA LR18689
UL E79133

General

Product Family Quick Disconnects
Series [19606](#)
Comments Funnel Entry
Crimp Quality Equipment Yes
Insulated Fully
Overview [Standard Quick-Disconnect Terminals](#)
Product Name InsulKrimp
Type Quick Disconnect
UPC 800753117969

Physical

Barrel Type Closed
Color - Resin Yellow
Flammability 94V-2
Gender Female
Glow-Wire Capable No
Insulation Nylon (PA)
Lock to Mating Part None
Material - Metal Brass
Material - Plating Mating Tin
Material - Plating Termination Tin
Material - Resin Nylon
Net Weight 1.236/g
Orientation Straight
Packaging Type Adhesive Tape on Reel
Plating min - Mating 2.540µm
Plating min - Termination 2.540µm
Polarized to Mating Part No
Tab Thickness 0.81mm
Tab Width 6.35mm
Temperature Range - Operating -65° to +105°C
Termination Interface: Style Crimp or Compression
Wire Insulation Diameter 6.10mm max.
Wire Size AWG 10, 12

Electrical


Voltage - Maximum 600V

Solder Process Data

Lead-freeProcess Capability N/A

Material Info

Engineering Number C-2293T

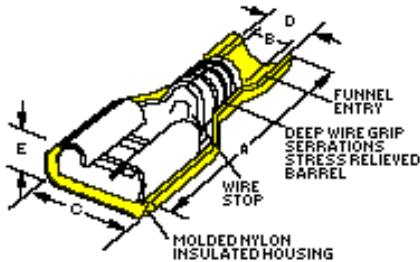

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per
-ED/01/2018 (15
January 2018)

Halogen-Free

Status

Low-Halogen

**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
Prop65	Compliant
RoHS Phthalates	Not Contained

Search Parts in this Series

[19606](#) Series

Reference - Drawing Numbers

Product Specification

Sales Drawing

PS-19902-008-001, PS-19902-015-001

SD-19003-005

This document was generated on 09/10/2018

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION