

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0002092118
Status: Active
Overview: Standard .093" Pin and Socket Connectors
Description: 2.36mm Diameter, Standard .093" Pin and Socket Crimp Terminal, Series 1380, Male, with Tin (Sn) Plated Brass Contact, 18-22 AWG, Bag

Documents:
[Drawing \(PDF\)](#)
[Product Specification PS-02-09 \(PDF\)](#)
[Packaging Specification PK-1190-003 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)


General
Product Family Crimp Terminals
Series 1380
Application Power, Wire-to-Wire
Crimp Quality Equipment Yes
Overview Standard .093" Pin and Socket Connectors
Packaging Alternative 02-09-2116 (Reel)
Product Name Standard .093"
UPC 800753746114

Physical
Durability (mating cycles max) 25
Gender Male
Material - Metal Brass
Material - Plating Mating Tin
Material - Plating Termination Tin
Net Weight 0.206/g
Packaging Type Bag
Plating min - Mating 0.508µm
Plating min - Termination 0.508µm
Termination Interface: Style Crimp or Compression
Wire Insulation Diameter 1.52-3.05mm
Wire Size AWG 18, 20, 22
Wire Size mm² N/A

Solder Process Data
Lead-freeProcess Capability N/A

Material Info
Engineering Number 1380-(P901)L

Reference - Drawing Numbers
Packaging Specification PK-1190-003
Product Specification PS-02-09
Sales Drawing SD-1380-*

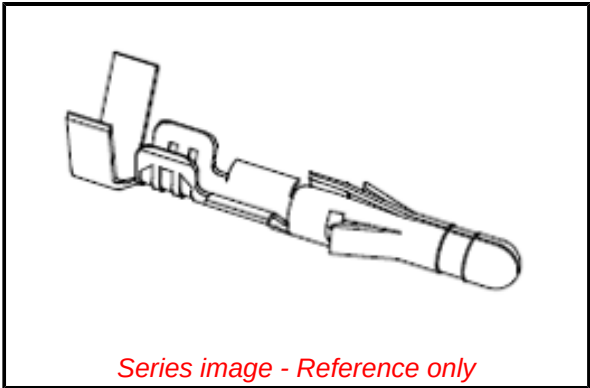

Series image - Reference only

EU ELV
Not Relevant

EU RoHS	China RoHS
Compliant REACH SVHC Not Contained Per - ED/61/2018 (27 June 2018) Halogen-Free Status Low-Halogen For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
1380 Series

Use With
1619 Plug or Receptacle Housing,
1545 Plug or Receptacle Housing, 1396
Plug or Receptacle Housing, 1490 Plug
or Receptacle Housing, 2629 Plug or
Receptacle Crimp Housings, 1261 Plug or
Receptacle Housing, 1292 Plug or Recept