

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0002095143
Status: Active
Overview: Standard .093" Pin and Socket Connectors
Description: 2.36mm Diameter, Standard .093" Pin and Socket Crimp Terminal, Series 1381, Female, with Gold (Au) Plated Brass Contact, 18-22 AWG, Reel

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-43660-9999-001 \(PDF\)](#)

General

Product Family Crimp Terminals
Series 1381
Application Power, Wire-to-Wire
Crimp Quality Equipment Yes
Overview Standard .093" Pin and Socket Connectors
Packaging Alternative 02-09-5142 (Loose)
Product Name Standard .093"
UPC 800754230094

Physical

Gender Female
Material - Metal Brass
Material - Plating Mating Gold
Material - Plating Termination Nickel
Net Weight 0.330/g
Packaging Type Reel
Plating min - Mating 0.381µm
Plating min - Termination 0.762µm
Termination Interface: Style Crimp or Compression
Wire Insulation Diameter 1.52-3.05mm
Wire Size AWG 18, 20, 22
Wire Size mm² N/A

Solder Process Data


Lead-freeProcess Capability N/A

Material Info

Engineering Number 1381-A(P550)

Reference - Drawing Numbers

Product Specification PS-43660-9999-001
Sales Drawing SD-1381-*

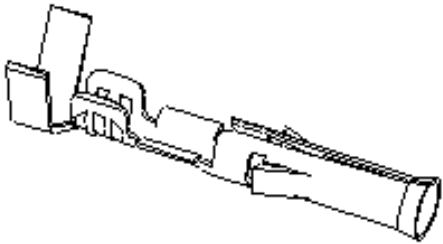

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant
REACH SVHC

Not Contained Per -
ED/61/2018 (27 June
2018)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

1381 Series