

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0003121046](#)
Status: **Active**
Description: 3.18mm Diameter, HCS125, Pin and Socket Receptacle Housing, Single Row, 4 Circuits, Natural (Translucent)

Documents:
[3D Model](#) [Product Specification PSX-42179-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification
CSA LR19980
UL E29179

General
Product Family Crimp Housings
Series [42179](#)
Application Power, Wire-to-Wire
Product Name HCS-125
UPC 800754232685


Physical
Circuits (maximum) 4
Color - Resin Natural
Flammability 94V-2
Gender Receptacle
Glow-Wire Capable No
Lock to Mating Part Yes
Material - Resin Nylon
Net Weight 4.747/g
Number of Rows 1
Packaging Type Bag
Panel Mount No
Pitch - Mating Interface 8.38mm
Polarized to Mating Part Yes
Stackable No
Temperature Range - Operating -40° to +105°C

Electrical
Current - Maximum per Contact 20.0A

Solder Process Data
Lead-freeProcess Capability N/A

Material Info
Engineering Number 42179-4R1

Reference - Drawing Numbers
Product Specification PSX-42179-001
Sales Drawing 421790000-SD-000

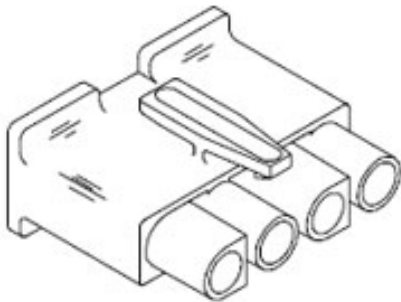

Series image - Reference only

EU ELV
Not Relevant

EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - ED/61/2018 (27 June 2018)	
Halogen-Free Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[42179 Series](#)

Mates With
[03-12-2045](#) , [03-12-2046](#)

Use With
[1900 Male Crimp Terminals](#), [1901](#) , [2046](#) , [2047](#) , [42546](#) , [42547](#) , [42554](#) , [42555](#)