

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0347960202](#)
Status: **Active**
Overview: [MX150™ Unsealed Connector System](#)
Description: MX150 Cable Unsealed Female Connector, Single Row, 2 Circuits, Polarization B, Natural

Documents:
[3D Model](#) [Packaging Specification PK-31301-695-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General
Product Family Crimp Housings
Series [34796](#)
Application Power, Wire-to-Wire
Overview [MX150™ Unsealed Connector System](#)
Polarization B
Product Name MX150 Unsealed
UPC 884982969469


Physical
Circuits (maximum) 2
Color - Resin Natural
Gender Receptacle
Glow-Wire Capable No
Keying to Mating Part Yes
Lock to Mating Part Yes
Material - Resin PBT
Net Weight 2.010/g
Number of Rows 1
Packaging Type Bag
Panel Mount No
Pitch - Mating Interface 3.50mm
Pitch - Termination Interface 3.50mm
Polarized to Mating Part Yes
Stackable No
Temperature Range - Operating -40° to +105°C

Electrical
Current - Maximum per Contact 22.0A

Solder Process Data
Lead-freeProcess Capability N/A

Material Info

Reference - Drawing Numbers
Packaging Specification PK-31301-695-001
Sales Drawing SD-34796-001

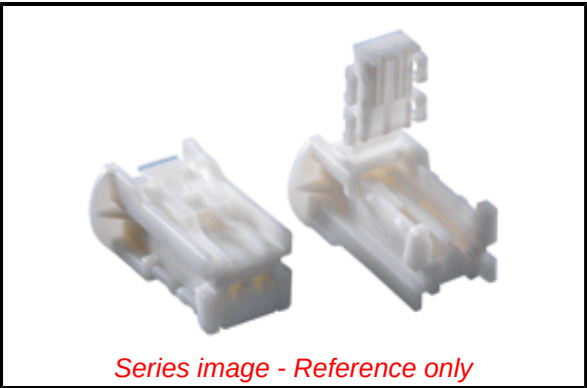

Series image - Reference only

EU ELV
Compliant

EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - ED/61/2018 (27 June 2018)	
Halogen-Free	
Status	
Not Relevant	
For more information, please visit Contact US	
China ROHS	Not Relevant
ELV	Compliant
RoHS Phthalates	Not Contained

Search Parts in this Series
[34796](#) Series

Mates With
[34797](#) 3.50mm Pitch MX150 Cable Unsealed Male

Use With
MX150 Female Terminal [33012-2021](#) , [33012-2022](#) , [33012-2023](#) , [33012-3021](#) , [330 12-3022](#) , [33012-3023](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION