

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0350230008](#)
Status: **Active**
Description: 2.00mm Pitch Board-in Crimp Housing, 8 Circuits, Natural

Documents:

[3D Model](#) [Packaging Specification PK-35023-001-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-35023-001-001 \(PDF\)](#)

Agency Certification

CSA LR19980
 UL E29179

General

Product Family Crimp Housings
 Series [35023](#)
 Application Signal
 Product Name Board-in
 UPC 800753514515

Physical

Circuits (maximum) 8
 Color - Resin Natural
 Flammability 94V-0
 Gender Receptacle
 Glow-Wire Capable No
 Material - Resin Nylon
 Net Weight 0.151/g
 Number of Rows 1
 Packaging Type Bag
 Panel Mount No
 Pitch - Mating Interface 2.00mm
 Stackable No
 Temperature Range - Operating -40° to +105°C


Solder Process Data

Lead-freeProcess Capability N/A

Material Info

Reference - Drawing Numbers

Packaging Specification PK-35023-001-001
 Product Specification PS-35023-001-001
 Sales Drawing SD-35023-001

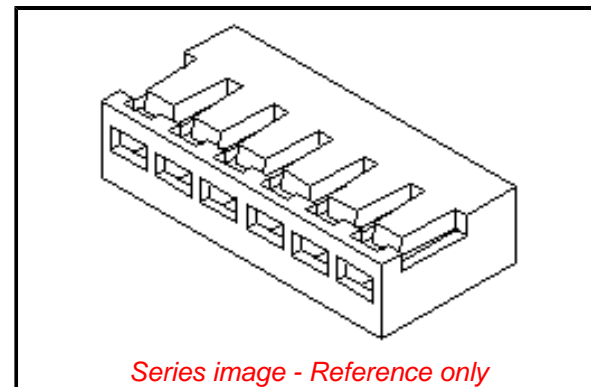

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
 ED/61/2018 (27 June
 2018)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Compliant

Not Contained

Search Parts in this Series

[35023 Series](#)

Use With

Straight Terminal [35044-9102](#) , [35044-9260](#)

Right Angle Terminal [35021-1201](#) ,
[35021-1301](#) , [35021-1360](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION