

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:	<u>0351810220</u>
Status:	Active
Description:	1.78mm Tab Multiple Wire-to-Wire Female Housing, 2 Circuits, Vertical, Type C

Documents:

3D Model Packaging Specification 351810200-100 (PDF)
 Drawing (PDF) RoHS Certificate of Compliance (PDF)
 Product Specification PS-35182-003-001 (PDF)

Agency Certification

CSA	LR19980
UL	E29179

General

Product Family	Crimp Housings
Series	<u>35181</u>
Application	Power, Wire-to-Wire
Product Name	N/A
UPC	800754376112


Physical

Circuits (maximum)	2
Color - Resin	Natural
Flammability	94V-0
Gender	Receptacle
Glow-Wire Capable	No
Material - Resin	Polyester
Net Weight	1.700/g
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	8.00mm
Stackable	No
Temperature Range - Operating	-40° to +120°C

Material Info

Reference - Drawing Numbers

Packaging Specification	351810200-100
Product Specification	PS-35182-003-001
Sales Drawing	SD-35181-022*

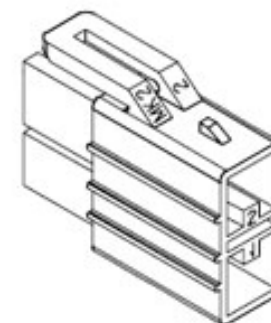

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/61/2018 (27 June
2018)

Halogen-Free

Status

Not Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
Prop65	Compliant
RoHS Phthalates	Not Contained

Search Parts in this Series

35181 Series

Mates With

35180 Wire-to-Wire Male Housing

Use With

35746 VersaBlade Crimp Terminal, 35182
VersaBlade Wire-to-Wire Male Housing TPA

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION