

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0395332008](#)
Status: **Active**
Overview: [Eurostyle Terminal Blocks](#)
Description: 5.08mm Pitch Eurostyle Vertical Plug, Rear Wire Entry, 8 Circuits

Documents:
[3D Model](#) [Product Specification PS-39500-001-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification
UL E48521

General
Product Family Terminal Blocks
Series [39533](#)
Application N/A
Comments Rear Wire Entry
Component Type Plug
Overview [Eurostyle Terminal Blocks](#)
Product Name ESE, Eurostyle Pluggable
Type Euro Block
UPC 822350523196


Physical
Circuits (Loaded) 8
Entry Angle Horizontal
Lock to Mating Part Yes
Number of Rows 1
Orientation Vertical
Panel Mount No
Pitch - Mating Interface 5.08mm
Pitch - Termination Interface 5.08mm
Polarized to Mating Part Yes
Stackable No
Temperature Range - Operating -40° to +105°C
Wire Size AWG 12, 14, 16, 18, 20, 22, 24, 26
Wire Size mm² 0.13-3.31

Electrical
Current - Maximum per Contact 18.0A
Voltage - Maximum 300V

Solder Process Data
Lead-freeProcess Capability N/A

Material Info

Reference - Drawing Numbers
Product Specification PS-39500-001-001
Sales Drawing SD-39533-002

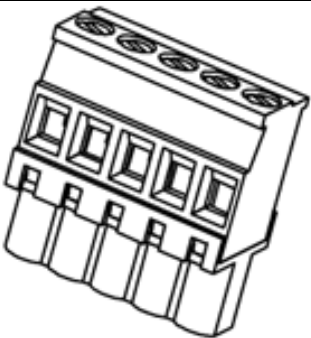

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

**Compliant with
Exemption 6(c)**

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS	50 Image
ELV	Not Relevant
Prop65	Missing Compliance Data
PropRisk	Cancer
PropRisk	Developmental toxicity
PropRisk	Reproductive toxicity
PropSub	Lead and its compounds
RoHS Phthalates	Not Reviewed

Search Parts in this Series

[39533](#) Series

Mates With

[39531](#) Vertical PCB Header, [39532](#)
Horizontal PCB Header, Most 5.08mm Pitch
Industry Standard PCB Headers, [39538](#)
Dual Level Header, Open Ends