

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0457501111](#)
Status: **Active**
Overview: [Mini-Fit Plus Connector System](#)
Description: Mini-Fit Plus Crimp Terminal, 18-20 AWG, Reel, Copper (Cu) Alloy, Tin (Sn)

Documents:

[Drawing \(PDF\)](#) [Packaging Specification PK-45750-001-001 \(PDF\)](#)
[Product Specification PS-45750-001-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Crimp Terminals
Series	45750
Application	Power, Wire-to-Board, Wire-to-Wire
Comments	Current = 13A max. per circuit when header is mated to a receptacle loaded with 45750 series terminals crimped to 16 AWG wire. . See Molex product specification PS-45750-001 for additional current de-rating information.
Crimp Quality Equipment	Yes
Overview	Mini-Fit Plus Connector System
Packaging Alternative	45750-1112 (Loose)
Product Name	Mini-Fit Plus
UPC	822350286015

Physical

Durability (mating cycles max)	100
Gender	Female
Material - Metal	Copper Alloy
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	0.150/g
Packaging Type	Reel
Plating min - Mating	2.540µm
Plating min - Termination	2.540µm
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.80-3.10mm
Wire Size AWG	18, 20
Wire Size mm ²	N/A

Electrical

Current - Maximum per Contact	13.0A
Voltage - Maximum	600V


Solder Process Data

Lead-freeProcess Capability	N/A
-----------------------------	-----

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-45750-001-001
Product Specification	PS-45750-001-001
Sales Drawing	SD-45750-001-001, SDIN-45750-001

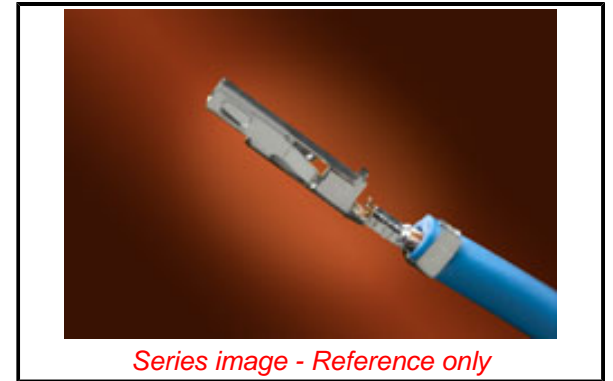

Series image - Reference only

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Not Contained Per - ED/61/2018 (27 June 2018)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Compliant

Not Contained

Search Parts in this Series

[45750](#) Series

Mates With

[46012](#) Mini-Fit Plus Crimp Terminal

Use With

[5557](#) Mini-Fit Jr., [30067](#) Mini-Fit TPA, [42474](#) Mini-Fit BMI Panel Mount, [43760](#) Mini-Fit BMI, [44516](#) Mini-Fit BMI Panel Mount Slide-N-Lock