

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** **0050375113**  
**Status:** **Active**  
**Overview:** Mini-SPOX Wire-to-Board Connector System  
**Description:** 2.50mm Pitch Mini-SPOX Wire-to-Board Crimp Housing, without Lock, 11 Circuits, Natural

**Documents:**

[3D Model](#) [Packaging Specification SPK-5264-001-001 \(PDF\)](#)  
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Product Specification PS-5264-001-001 \(PDF\)](#)

**Agency Certification**

UL E29179

**General**

Product Family Crimp Housings  
Series 5264  
Application Signal, Wire-to-Board  
Overview Mini-SPOX Wire-to-Board Connector System  
Product Name Mini-SPOX  
UPC 800753578401

**Physical**


Circuits (maximum) 11  
Color - Resin Natural  
Flammability 94V-0  
Gender Receptacle  
Glow-Wire Capable No  
Lock to Mating Part No  
Net Weight 594.600/mg  
Number of Rows 1  
Packaging Type Bag  
Panel Mount No  
Pitch - Mating Interface 2.50mm  
Polarized to Mating Part Yes  
Stackable No  
Temperature Range - Operating -40° to +105°C

**Material Info**

Engineering Number 5264-11

**Reference - Drawing Numbers**

Packaging Specification SPK-5264-001-001  
Product Specification PS-5264-001-001  
Sales Drawing SD-5264-N-001, SD-5264-N-002

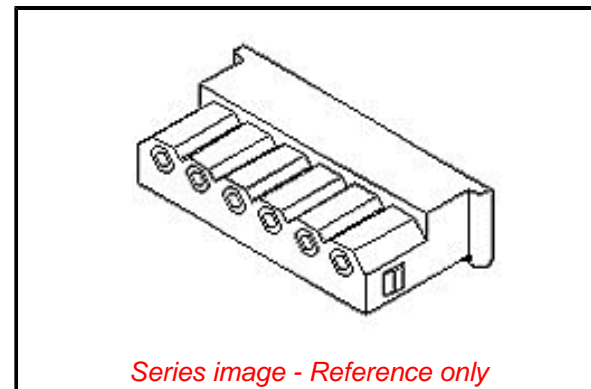

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
ED/61/2018 (27 June  
2018)

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

5264 Series

**Mates With**

5267 Mini-SPOX Vertical Shrouded PCB Header <br> 5268 Mini-SPOX Right Angle Shrouded PCB Header

**Use With**

5263 2.50mm Pitch Mini-SPOX Crimp Terminal