

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0527931270

Status:


Active

Overview:

FFC-FPC (SMT)

Description:

1.00mm Pitch Easy-On FFC/FPC Connector, Surface Mount, Right-Angle, Non-ZIF, Top Contact Style, 12 Circuits

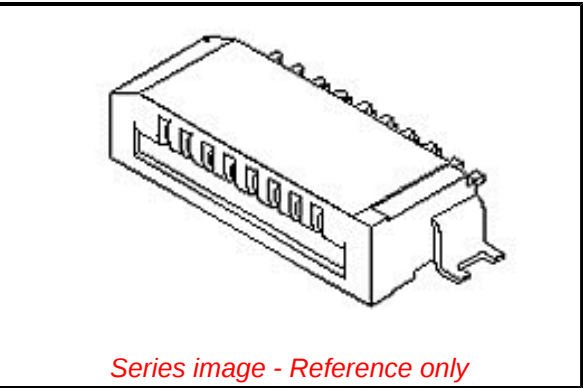

Documents:

3D Model

Drawing (PDF)

Product Specification PS-52793-014-001 (PDF)

Packaging Specification SPK-52793-001-001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification		
CSA		LR19980
UL		E29179
General		
Product Family		FFC/FPC Connectors
Series		52793
Overview		FFC-FPC (SMT)
Product Name		Easy-On
UPC		822348126545
Physical		
Actuator Type		Non-ZIF
Circuits (Loaded)		12
Contact Position		Top
Durability (mating cycles max)		10
Flammability		94V-0
Mated Height		3.10mm
Material - Metal		Phosphor Bronze
Net Weight		391.900/mg
Number of Rows		1
Orientation		Right Angle
PCB Locator		No
PCB Mounting		Surface Mount
PCB Retention		Yes
Packaging Type		Embossed Tape on Reel
Pitch - Mating Interface		1.00mm
Pitch - Termination Interface		1.00mm
Polarized to PCB		No
Stackable		No
Temperature Range - Operating		-20° to +85°C
Wire/Cable Type		FFC/FPC
Electrical		
Current - Maximum per Contact		0.5A
Voltage - Maximum		50V
Material Info		
Reference - Drawing Numbers		
Packaging Specification		SPK-52793-001-001
Product Specification		PS-52793-014-001
Sales Drawing		527930000-000, 527931000-000

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -

ED/61/2018 (27 June

2018)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit

Contact US

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

52793 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION