

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [5600230421](#)  
**Status:** **Active**  
**Overview:** [Mini50 Connection Systems](#)  
**Description:** CTX50 Receptacle Terminal, Unsealed, Tin Plating, M-Grip, D-Wind, Left Payoff

**Documents:**

<a href="#">Drawing (PDF)</a>	<a href="#">Application Specification AS-560023-001-FR-001 (PDF)</a>
<a href="#">Product Specification 5600230001-PS (PDF)</a>	<a href="#">Packaging Specification 313025040-000 (PDF)</a>
<a href="#">Product Specification TS-560023-001-001 (PDF)</a>	<a href="#">Packaging Specification PK-31301-319 (PDF)</a>
<a href="#">Application Specification AS-560023-001-001 (PDF)</a>	<a href="#">RoHS Certificate of Compliance (PDF)</a>
<a href="#">Application Specification AS-560023-001-CH-001 (PDF)</a>	<a href="#">Product Literature (PDF)</a>

**General**

Product Family	Crimp Terminals
Series	560023
Application	Power, Wire-to-Board
Crimp Quality Equipment	Yes
Overview	<a href="#">Mini50 Connection Systems</a>
Product Literature Order No	987650-5442
Product Name	CTX50
UPC	884982134065

**Physical**

Durability (mating cycles max)	10
Gender	Female
Grip Code	M
Material - Metal	Copper Alloy
Material - Plating Mating	Tin
Net Weight	0.049/g
Packaging Type	Reel
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	0.95-1.20mm
Wire Size AWG	N/A
Wire Size mm <sup>2</sup>	0.22

**Electrical**

Current - Maximum per Contact	4.0A
Voltage - Maximum	14V DC


**Solder Process Data**

Lead-freeProcess Capability	N/A
-----------------------------	-----

**Material Info**

**Reference - Drawing Numbers**

Application Specification	AS-560023-001-001, AS-560023-001-CH-001, AS-560023-001-FR-001
Packaging Specification	313025040-000, PK-31301-319
Product Specification	5600230001-PS, TS-560023-001-001
Sales Drawing	5600230001-000, SD-560023-002-000

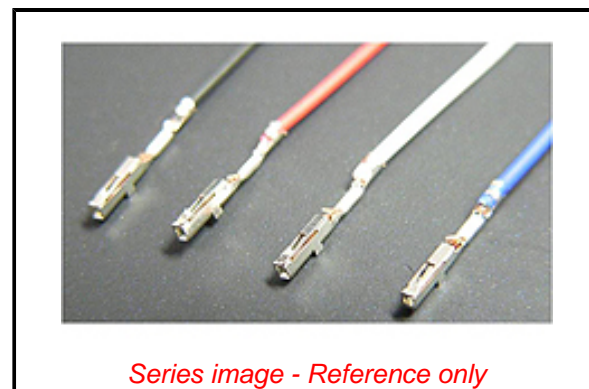

*Series image - Reference only*

**EU ELV**

**Compliant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per - ED/61/2018 (27 June 2018)

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Compliant

Not Contained

**Search Parts in this Series**

[560023 Series](#)

**Use With**

Mini50 Unsealed Single Row Receptacle [34791](#) , Mini50 Unsealed Dual Row Receptacle [34824](#)