

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0716607130

Status:


Active

Overview:

EBBI 50D Connector System

Description:

1.27mm Pitch EBBI 50D Receptacle, Vertical, Blind-Mate, 130 Circuits

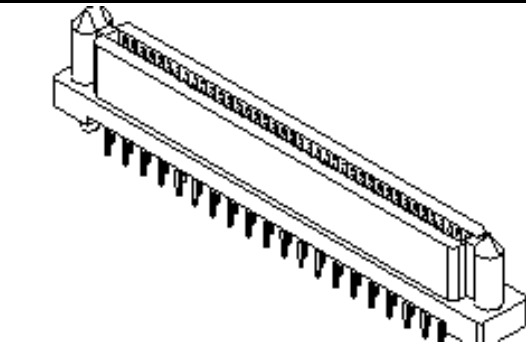

Series image - Reference only

Documents:

3D Model

RoHS Certificate of Compliance (PDF)

Drawing (PDF)

Agency Certification	
CSA	LR19980
UL	E29179
General	
Product Family	PCB Receptacles
Series	71660
Application	Board-to-Board, Signal
Overview	EBBI 50D Connector System
Product Name	EBBI
UPC	800753785182
Physical	
Circuits (Loaded)	130
Circuits (maximum)	130
Color - Resin	Black
Durability (mating cycles max)	2000
Flammability	94V-0
Glow-Wire Capable	No
Material - Metal	Phosphor Bronze
Material - Plating Mating	Gold
Material - Plating Termination	Tin
Material - Resin	High Temperature Thermoplastic
Net Weight	7.750/g
Number of Rows	2
Orientation	Vertical
PC Tail Length	2.79mm
PCB Locator	Yes
PCB Retention	Yes
PCB Thickness - Recommended	2.79mm
Packaging Type	Tray
Pitch - Mating Interface	1.27mm
Plating min - Mating	0.762µm
Plating min - Termination	0.254µm
Polarized to PCB	Yes
Temperature Range - Operating	-40° to +105°C
Termination Interface: Style	Through Hole
Electrical	
Current - Maximum per Contact	1.0A
Voltage - Maximum	30V
Solder Process Data	
Lead-freeProcess Capability	SMC&WAVE
Process Temperature max. C	260

Material Info

Reference - Drawing Numbers

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per - ED/61/2018 (27 June 2018)

Halogen-Free

Status

Low-Halogen

For more information, please visit

Contact US

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

71660 Series

Mates With

71661-7***|71661-25**

This document was generated on 10/05/2018

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION