

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0008700102

Status:


Active

Overview:

Mini-Latch Wire-to-Board System

Description:

2.50mm Pitch Mini-Latch Wire-to-Wire Male Crimp Terminal, Reel

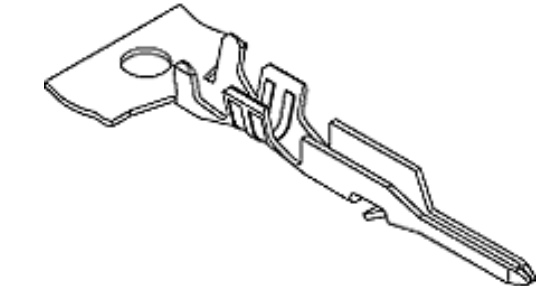

Series image - Reference only

Documents:

3D Model

Drawing (PDF)

Product Specification PS-51191-003 (PDF)

Packaging Specification SPK-5241-001-001 (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Crimp Terminals
Series	5241
Application	Signal, Wire-to-Wire
Crimp Quality Equipment	Yes
Overview	Mini-Latch Wire-to-Board System
Packaging Alternative	08-70-0103 (Loose)
Product Name	Mini-Latch
UPC	800753640511
Physical	
Gender	Male
Material - Metal	Brass
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	65.400/mg
Packaging Type	Reel
Plating min - Mating	0.889µm
Plating min - Termination	0.889µm
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.15-1.90mm
Wire Size AWG	22, 24, 26, 28
Wire Size mm²	N/A
Material Info	
Engineering Number	5241T
Reference - Drawing Numbers	
Packaging Specification	SPK-5241-001-001
Product Specification	PS-51191-003
Sales Drawing	SD-5241*

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -

ED/61/2018 (27 June

2018)

Halogen-Free

Status

Low-Halogen

For more information, please visit

Contact US

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

5241 Series

Mates With

50802 Female Crimp Terminal

Use With

5240

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION