

PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION


**Part Number:** [0877580416](#)  
**Status:** **Active**  
**Overview:** [Milli-Grid Connector System](#)  
**Description:** 2.00mm Pitch Milli-Grid Header, Through Hole, Vertical, 4 Circuits, 0.38µm Gold (Au)  
Selective Plating, Pocket Tray Packaging, Lead-Free

**Documents:**  
[3D Model](#)  
[Drawing \(PDF\)](#)  
[Product Specification PS-87761-100-001 \(PDF\)](#)  
[Packaging Specification PK-89990-487-001 \(PDF\)](#)  
[RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**  
UL E29179

**General**  
Product Family PCB Headers  
Series [87758](#)  
Application Board-to-Board, Signal  
Overview [Milli-Grid Connector System](#)  
Product Name Milli-Grid  
UPC 822348273522

**Physical**  
Breakaway Yes  
Circuits (Loaded) 4  
Circuits (maximum) 4  
Color - Resin Black  
Durability (mating cycles max) 100  
First Mate / Last Break No  
Flammability 94V-0  
Glow-Wire Capable No  
Guide to Mating Part No  
Keying to Mating Part None  
Lock to Mating Part None  
Mated Height 4.00mm  
Material - Metal Phosphor Bronze  
Material - Plating Mating Gold  
Material - Plating Termination Tin  
Material - Resin Nylon  
Net Weight 0.101/g  
Number of Rows 2  
Orientation Vertical  
PC Tail Length 2.60mm  
PCB Locator No  
PCB Retention None  
PCB Thickness - Recommended 1.60mm  
Packaging Type Tray  
Pitch - Mating Interface 2.00mm  
Pitch - Termination Interface 2.00mm  
Plating min - Mating 0.381µm  
Polarized to Mating Part No  
Polarized to PCB No  
Shrouded No  
Stackable No  
Surface Mount Compatible (SMC) Yes  
Temperature Range - Operating -55° to +105°C  
Termination Interface: Style Through Hole

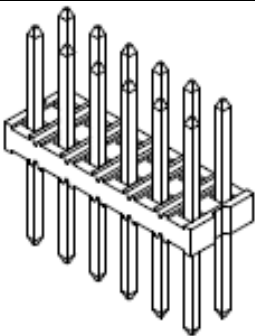

Series image - Reference only

**EU ELV**  
**Not Relevant**

**EU RoHS** **China RoHS**  
**Compliant**  
**REACH SVHC**  
Not Contained Per -  
ED/61/2018 (27 June  
2018)  
**Halogen-Free**  
**Status**  
**Not Low-Halogen**

For more information, please visit [Contact US](#)  
  
China ROHS Green Image  
ELV Not Relevant  
RoHS Phthalates Not Contained

**Search Parts in this Series**  
[87758](#) Series

**Mates With**  
Milli-Grid Vertical Through Hole Receptacle  
[79107](#) , [78787](#) , Milli-Grid Flex-to-Board  
Vertical Receptacle [79108](#) , Milli-Grid  
Vertical Surface Mount Receptacle [79109](#) ,  
[78788](#) , Milli-Grid Top Entry Surface Mount  
Receptacle [87381](#) , Milli-Grid Crimp Housing  
[51110](#)

**Electrical**

|                               |      |
|-------------------------------|------|
| Current - Maximum per Contact | 2.0A |
| Voltage - Maximum             | 125V |

**Solder Process Data**

|                                                |      |
|------------------------------------------------|------|
| Duration at Max. Process Temperature (seconds) | 003  |
| Lead-freeProcess Capability                    | WAVE |
| Max. Cycles at Max. Process Temperature        | 001  |
| Process Temperature max. C                     | 250  |

**Material Info**

**Reference - Drawing Numbers**

|                         |                  |
|-------------------------|------------------|
| Packaging Specification | PK-89990-487-001 |
| Product Specification   | PS-87761-100-001 |
| Sales Drawing           | SD-87758-107-001 |

This document was generated on 10/08/2018

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**