

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0877592650](#)
Status: **Active**
Overview: [Milli-Grid Connector System](#)
Description: Milli-Grid Header, Surface Mount, Vertical, 26 Circuits, 0.38µm Gold (Au) Selective Plating, with Press-fit Plastic Pegs, Lead-Free

Documents:

[3D Model](#) [Packaging Specification PK-89990-475-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-87761-100-001 \(PDF\)](#)

Agency Certification

UL E29179

General


Product Family PCB Headers
Series [87759](#)
Application Board-to-Board, Signal
Overview [Milli-Grid Connector System](#)
Product Name Milli-Grid
UPC 822348283613

Physical

Breakaway Yes
Circuits (Loaded) 26
Circuits (maximum) 26
Color - Resin Black
Durability (mating cycles max) 100
First Mate / Last Break No
Flammability 94V-0
Glow-Wire Capable No
Guide to Mating Part No
Keying to Mating Part None
Lock to Mating Part None
Mated Height 3.80mm
Material - Metal Phosphor Bronze
Material - Plating Mating Gold
Material - Plating Termination Tin
Material - Resin High Temperature Thermoplastic
Net Weight 0.651/g
Number of Rows 2
Orientation Vertical
PCB Locator Yes
PCB Retention None
Packaging Type Tube
Pitch - Mating Interface 2.00mm
Pitch - Termination Interface 2.00mm
Plating min - Mating 0.381µm
Polarized to Mating Part No
Polarized to PCB No
Shrouded No
Stackable Yes
Temperature Range - Operating -55° to +125°C
Termination Interface: Style Surface Mount

Electrical

Current - Maximum per Contact 2.0A

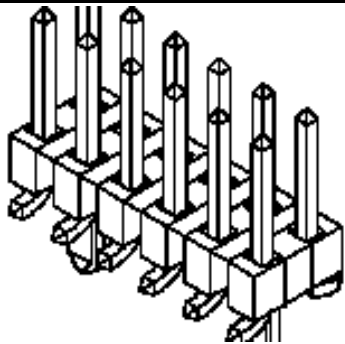

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/61/2018 (27 June
2018)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS Green Image
ELV Not Relevant
RoHS Phthalates Not Contained

Search Parts in this Series

[87759](#) Series

Mates With

Milli-Grid Vertical Through Hole Receptacle [79107](#) , [78787](#) , Milli-Grid Flex-to-Board Vertical Receptacle [79108](#) , Milli-Grid Vertical Surface Mount Receptacle [79109](#) , [78788](#) , Milli-Grid Top Entry Surface Mount Receptacle [87381](#) , Milli-Grid Crimp Housing [51110](#)

Voltage - Maximum	125V
Solder Process Data	
Duration at Max. Process Temperature (seconds)	010
Lead-freeProcess Capability	REFLOW
Max. Cycles at Max. Process Temperature	003
Process Temperature max. C	260
Material Info	
Reference - Drawing Numbers	
Packaging Specification	PK-89990-475-001
Product Specification	PS-87761-100-001
Sales Drawing	SD-87759-113-001

This document was generated on 10/03/2018

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION