

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0901560156](#)
Status: **Active**
Description: 2.54mm Pitch C-Grid III Crimp Housing Single Row, 16 Circuits

Documents:

[3D Model](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Drawing \(PDF\)](#)

Agency Certification

UL E29179


General

Product Family Crimp Housings
 Series [90156](#)
 Application Signal, Wire-to-Board
 Product Name C-Grid III
 UPC 800753534247

Physical

Breakaway No
 Circuits (maximum) 16
 Color - Resin Black
 Gender Receptacle
 Glow-Wire Capable No
 Lock to Mating Part Yes
 Material - Resin PPO
 Net Weight 1.218/g
 Number of Rows 1
 Packaging Type Bag
 Panel Mount No
 Pitch - Mating Interface 2.54mm
 Temperature Range - Operating -55° to +105°C

Material Info

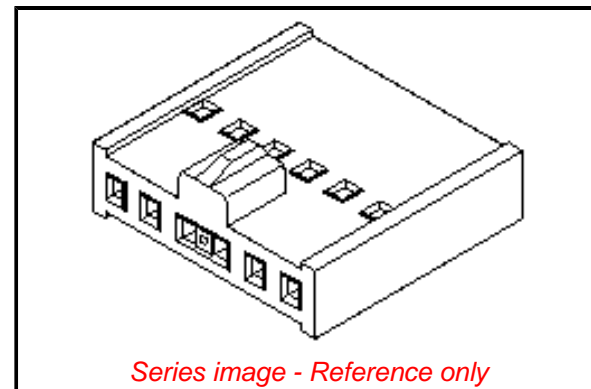

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
 ED/30/2017 (7 July
 2017)

Halogen-Free

Status

Low-Halogen

**Need more information on product
 environmental compliance?**

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any
 non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[90156](#) Series

Mates With

[90120](#) , [90121](#) , [90136](#)

Use With

[90119](#)