

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0009507081

Status:

Active

Overview:

KK® Interconnect System - Molex

Description:

KK 3.96mm Crimp Terminal Housing, 8 Circuits, Natural

Documents:

3D Model


Packaging Specification PK-2139-001-001 (PDF)

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Product Specification PS-08-50-001 (PDF)

Agency Certification	
UL	E29179
General	
Product Family	Crimp Housings
Series	2139
Application	Power, Wire-to-Board
Overview	KK® Interconnect System - Molex
Product Name	KK 396
UPC	800753531543
Physical	
Circuits (maximum)	8
Color - Resin	Natural
Flammability	94V-2
Gender	Receptacle
Glow-Wire Capable	No
Material - Resin	Nylon
Net Weight	2.048/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	3.96mm
Temperature Range - Operating	See Product Specification
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Engineering Number	2139-8C
Reference - Drawing Numbers	
Packaging Specification	PK-2139-001-001
Product Specification	PS-08-50-001
Sales Drawing	SD-2139

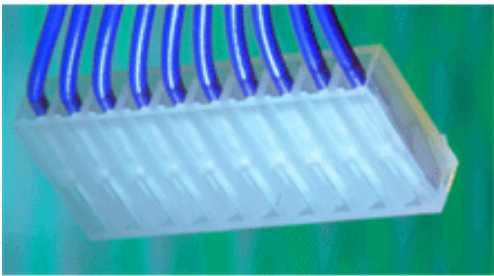

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

Green Image

REACH SVHC

Not Contained Per -

ED/61/2018 (27 June

2018)

Halogen-Free

Status

Low-Halogen

For more information, please visit

Contact US

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

Search Parts in this Series

2139 Series

Mates With

KK 396 Headers: 41771 , 41772 , 41791 ,

41792 , 42491 , 42492 , KK 396 Breakaway

Headers: 41661 , 41662 , 41671 , 41672

Use With

2478 Crimp Terminals for 18-24 AWG, 2578

Crimp Terminals for 22-26 AWG

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION