




151 SERIES

Power Pin Header Right Angle 4 mm Pitch

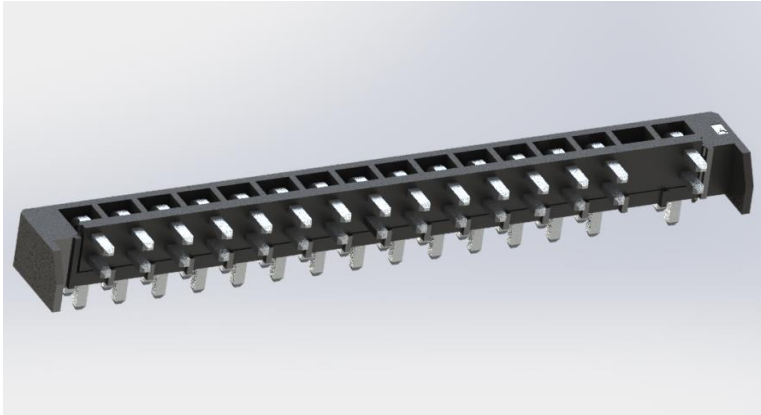


Features:

- 20A / Pin
- Board to Board Type
- Total number of contacts : 30
- Terminal 3 & Terminal 4 Removed
- Height : 6.8 mm
- Application : Server, Data Storage
- Part Number: 151-832-426-900

Specifications:

Housing Material	High Temperature Thermoplastic UL-94V-0
Contact Material	Copper Alloy
Contact Plating	Tin Plating
Current Rating	20 A ΔT 30°C
Voltage Rating	500 V AC
Contact Resistance	Initial: 50m Ω Max. After Test: ΔR 20m Ω
Dielectric Withstand Voltage	500 V AC for 60s
Insulation Resistance	100 M Ω Min.
Operating Temperature	-55°C to +85°C

Recommended PCB Layout:

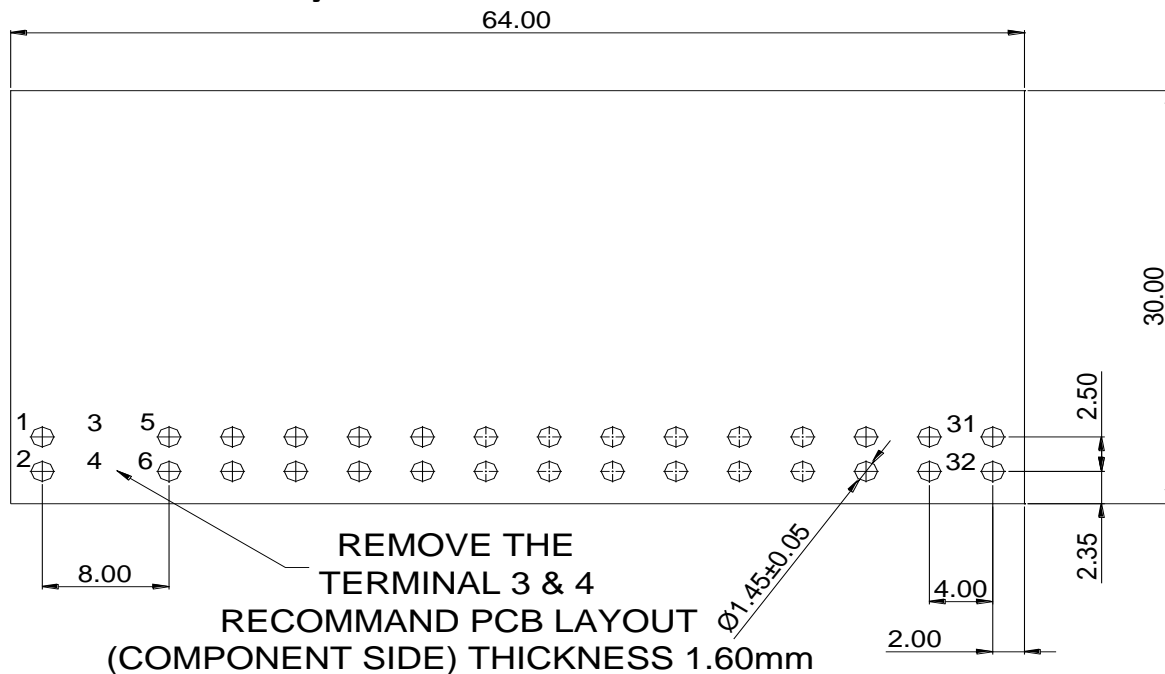



151 SERIES

Power Pin Header Right Angle 4 mm Pitch

Recommended PCB Layout:

