

Wiha Slotted Insert & Power Bits



720 Slotted Insert Bits. 5/16" Hex Drive, Length 41mm

Item					
No.	mm	Inch	mm	pkg.	lbs.
72049	8.0	.315	1.6	10	.31
72050	10.0	.393	1.6	10	.46
72051	12.0	.472	2.0	10	.56



2 bit pack



720 Slotted Insert Bit Packs, 1"

CVM S2 modified tool steel. 5/16" Hex Drive.

Item					
No.	mm	mm	Inch	mm	lbs.
72031	1.6	8.0	.315	41	.08
72039	1.6	10.0	.393	41	.10
72047	2.0	12.0	.472	41	.12



740 Slotted Power Bits, 1/4" Hex Drive, Length 2.75"/70mm

Item					
No.	mm	Inch	mm	Inch	pkg.
74033	2.5	.098	0.4	.015	10
74034	3.0	.118	0.5	.020	10
74035	3.5	.139	0.6	.024	10
74036	4.0	.157	0.8	.020	10
74039	5.5	.216	1.0	.032	10
74041	6.5	.255	1.2	.039	10

2 bit pack



739 Slotted Power Bits, 1/4" Hex Drive, Length 2.75"/70mm 2 bit pack

Item					
No.	mm	Inch	mm	Inch	pkg.
73905	2.5	.098	0.4	.015	1
73906	3.0	.118	0.5	.020	1
73907	3.5	.139	0.6	.024	1
73908	4.0	.157	0.8	.020	1
73909	5.5	.216	1.0	.032	1
73910	6.5	.255	1.2	.039	1

2 bit pack



710 Slotted Insert Bit Packs, 1" CVM S2 modified tool steel.

Item					
No.	mm	mm	Inch	mm	lbs.
71051	0.6	4.5	.177	25	.03
71052	0.8	5.5	.216	25	.03
71053	1.2	6.0	.255	25	.03
71054	1.6	8.0	.315	25	.03



71055 Slotted Insert Bit Packs, 1" CVM S2 modified tool steel. Extra hard with natural finish. Exact fit machined tips. 3 pc. bit pack.

Set includes the following bits:


Slotted:			
wt. .04	4.5, 5.5, 6.0 x 1"	(25mm)	



740 Slotted Power Bits. 1/4" Hex Drive, Length 2.0"/50mm 10pk. weight .20 lbs.

Item					
No.	mm	Inch	mm	Inch	pkg.
74003	3.0	.118	0.5	.020	10
74006	3.5	.139	0.6	.024	10
74009	4.0	.157	0.5	.020	10
74010	4.0	.157	0.8	.030	10
74012	4.5	.177	0.6	.024	10
74015	5.5	.216	0.8	.032	10
74018	6.5	.255	1.2	.039	10
74021	8.0	.315	1.2	.039	10
74023	8.0	.315	1.6	.063	10


2 bit pack

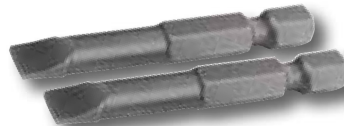

740 Slotted Power Bit Packs, 2"

CVM S2 modified tool steel.

Item			
No.	mm	mm	lbs.
74061	3.0	50	.05
74062	3.5	50	.05
74063	4.0	50	.05
74064	4.0	50	.05
74065	4.5	50	.05
74066	5.5	50	.05
74067	6.5	50	.06
74068	8.0	50	.08
74069	8.0	50	.08

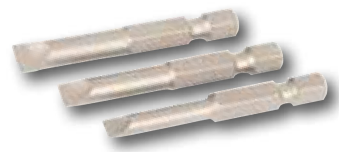

74050 Slotted Power Bit Packs, 2" CVM

S2 modified tool steel. Extra hard with natural finish. Exact fit machined tips. 3 pc. bit pack.

Set includes the following bits:

Slotted:		
wt. .08	4.5, 5.5, 6.5 x 2"	(50mm)



743 Slotted and Phillips Double End Bits, 1/4" Hex Drive, Length 2.36"/60mm

Item					
No.	mm	Size	mm	pkg.	lbs.
74303	4.5 x	1	60	10	.22
74306	5.5 x	2	60	10	.30
74309	7.0 x	3	60	10	.32


Wiha Slotted Power Blades



760 Slotted Power Blades

S2 modified tool steel. Hardened & tempered to HRC 60. Blades fit CentroFix power blade handle. OAL 90mm/3.5".

Item			
No.	mm	lbs.	pkg.
76035	2.5	.02	1
76036	3.0	.02	1
76037	4.5	.03	1
76038	5.5	.03	1
76039	6.0	.04	1

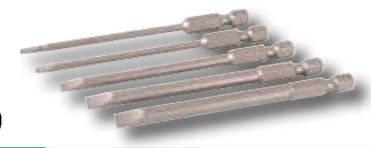

76093 5 Piece Slotted Blade Set

Item		Set includes:
No.	lbs.	Slotted: 2.5, 3.0, 4.5,
76093	.16	5.5, 6.0mm x 90mm