


KEMET, NBL, Transducers, Single-layer

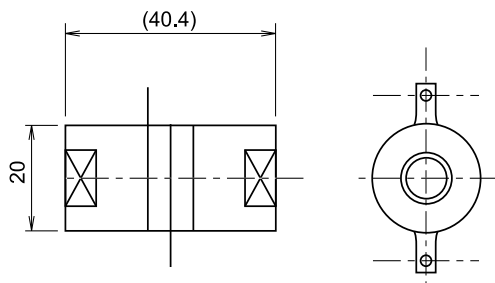

Dimensions	
D	20mm NOM
L	40.4mm NOM

Packaging Specifications	
Weight:	35
Packaging:	Bulk Tray, Box
Packaging Quantity:	160

General Information	
Style:	Bolt-On
Description:	Langevin Bolt-On Transducers
RoHS:	Yes
Notes:	Straight Construction

Specifications	
Series:	NBL
Capacitance:	1250 pF
Resonant Frequency:	60 kHz
Dynamic Admittance:	20msec
Mechanical Q:	400 Qm
Allowable Velocity:	40 cm/S
Allowable Power:	3.7
Temperature Range:	-40/+120C