

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

5023800500

Status:


Active

Overview:

CLIK-Mate Wire-to-Board Connectors

Description:

1.25mm Pitch CLIK-Mate Wire-to-Board Housing, Single Row, Positive Lock, 5 Circuits, White

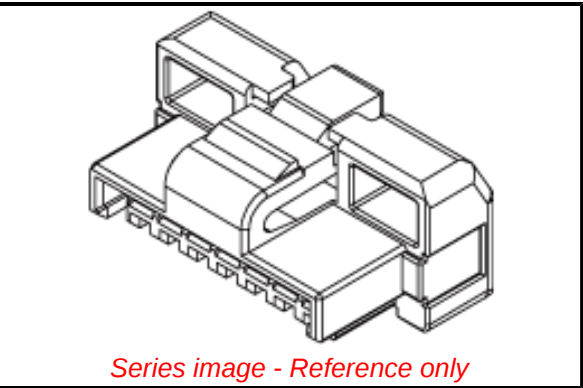

Documents:

3D Model

Application Specification AS-502380-001-001 (PDF)

Drawing (PDF)

Application Specification AS-502380-002-001 (PDF)

Product Specification PS-502382-001-001 (PDF)

RoHS Certificate of Compliance (PDF)

Product Specification PS-502382-002-001 (PDF)

General	
Product Family	Crimp Housings
Series	502380
Application	Signal, Wire-to-Board
Overview	CLIK-Mate Wire-to-Board Connectors
Product Name	CLIK-Mate
UPC	822350894876
Physical	
Breakaway	No
Circuits (maximum)	5
Color - Resin	White
Gender	Plug
Glow-Wire Capable	No
Keying to Mating Part	Yes
Lock to Mating Part	Yes
Material - Resin	Polyester
Net Weight	169.000/mg
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	1.25mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C
Electrical	
Current - Maximum per Contact	1.0A
Material Info	
Reference - Drawing Numbers	
Application Specification	AS-502380-001-001, AS-502380-002-001
Product Specification	PS-502382-001-001, PS-502382-002-001
Sales Drawing	SD-502380-001, SD-502380-002

EU ELV
Not Relevant

EU RoHS
Compliant

REACH SVHC
Not Contained Per -
ED/61/2018 (27 June
2018)

Halogen-Free
Status
Not Low-Halogen

For more information, please visit [Contact US](#)

China RoHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series
502380 Series

Mates With
502382 PCB Receptacle, 502386 PCB Receptacle

Use With
502381 Crimp Terminal

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION