

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [5025983393](#)
Status: **Active**
Overview: FFC-FPC (SMT)
Description: 0.30mm Pitch Easy-On Back Flip FPC Connector, Right-Angle, Surface Mount, Dual Contact Style, 1.15mm Mated Height, 33 Circuits

Documents:

[3D Model](#) [Packaging Specification SPK-502598-001-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-502598-002-001 \(PDF\)](#)

General

Product Family FFC/FPC Connectors
Series [502598](#)
Overview [FFC-FPC \(SMT\)](#)
Product Name Easy-On
UPC 887191146423

Physical

Actuator Type Flip
Circuits (Loaded) 33
Color - Resin Black, White
Contact Position Dual
Durability (mating cycles max) 10
Mated Height 1.15mm
Material - Metal Copper Alloy, Phosphor Bronze
Material - Plating Mating Gold
Material - Plating Termination Gold, Tin
Net Weight 85.310/mg
Number of Rows 1
Orientation Right Angle
PCB Locator No
PCB Mounting Surface Mount
PCB Retention Yes
Packaging Type Embossed Tape on Reel
Pitch - Mating Interface 0.30mm
Polarized to PCB Yes
Stackable No
Temperature Range - Operating -40° to +105°C
Wire/Cable Type FPC only


Electrical

Current - Maximum per Contact 0.2A
Voltage - Maximum 50V AC (RMS)/DC

Material Info

Reference - Drawing Numbers

Packaging Specification SPK-502598-001-001
Product Specification PS-502598-002-001
Sales Drawing SD-502598-003, SD-502598-004

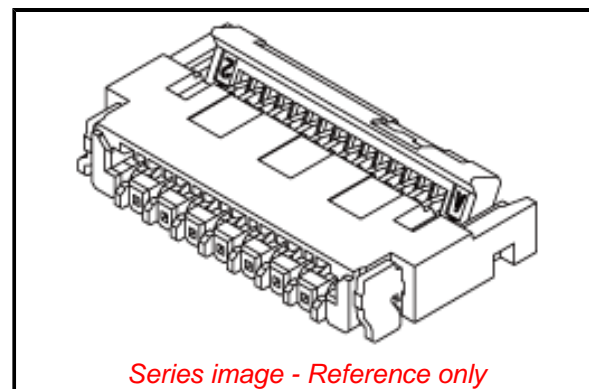

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/61/2018 (27 June
2018)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[502598 Series](#)

Mates With

[15015](#) 0.30mm Pitch Premo-Flex Etched Polyimide Jumper