

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 5033204160

Status: **Active**

Overview: FFC-FPC (SMT)

Description: 0.25mm Pitch Easy-On FPC Connector, 1.65mm Mated Height, Right-Angle, Surface Mount, Bottom Contact Style, 41 Circuits

Documents:


3D Model

Drawing (PDF)

Product Specification PS-503320-001-001 (PDF)

Packaging Specification SPK-503320-001-001 (PDF)

[RoHS Certificate of Compliance \(PDF\)](#)

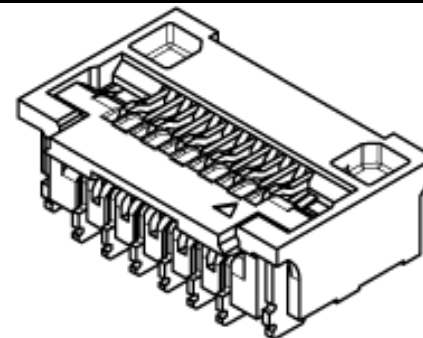

Series image - Reference only

General

Product Family	FFC/FPC Connectors
Series	503320
Overview	FFC-FPC (SMT)
Product Name	Easy-On
UPC	883906428105

Physical

Actuator Type	Flip
Circuits (Loaded)	41
Contact Position	Bottom
Durability (mating cycles max)	10
Mated Height	1.65mm
Material - Metal	Copper Alloy
Material - Plating Mating	Gold
Material - Plating Termination	Gold
Net Weight	82.311/mg
Number of Rows	1
Orientation	Right Angle
PCB Locator	No
PCB Mounting	Surface Mount
PCB Retention	Yes
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	0.25mm
Polarized to PCB	Yes
Stackable	No
Temperature Range - Operating	-40° to +85°C
Wire/Cable Type	FPC only

Electrical

Current - Maximum per Contact	0.3A
Voltage - Maximum	50V

Material Info

Reference - Drawing Numbers

Packaging Specification	SPK-503320-001-001
Product Specification	PS-503320-001-001
Sales Drawing	5033200000-000, 5033201000-000

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/61/2018 (27 June
2018)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

503320 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION