

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0738380003**
Status: **Active**
Overview: SL Modular Connectors
Description: 2.54mm SL Crimp Housing, Single Row, Version N, TPA with Positive Latch, 3 Circuits, Natural

Documents:

[3D Model](#) [Packaging Specification PK-70873-0540 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-73838-005-001 \(PDF\)](#)

General

Product Family Crimp Housings
Series 73838
Application Signal, Wire-to-Board, Wire-to-Wire
Comments Terminal Position Assurance (TPA) Piece
Overview SL Modular Connectors
Product Name SL
UPC 800753951587

Physical

Circuits (maximum) 3
Color - Resin Natural
Gender Receptacle
Glow-Wire Capable No
Material - Resin Polyester Alloy
Net Weight 0.068/g
Number of Rows 1
Packaging Type Bag
Panel Mount No
Pitch - Mating Interface 2.54mm
Stackable No
Temperature Range - Operating -40° to +105°C


Solder Process Data

Lead-freeProcess Capability N/A

Material Info

Reference - Drawing Numbers

Packaging Specification PK-70873-0540
Product Specification PS-73838-005-001
Sales Drawing SD-73838-004

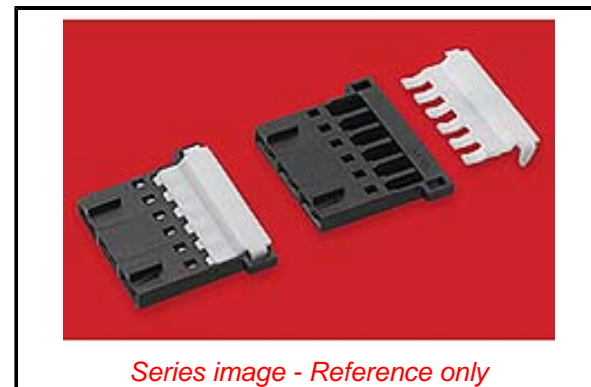

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per
-ED/01/2018 (15
January 2018)

Halogen-Free

Status

Not Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

73838 Series

Mates With

70018 , 70543 , 70545 , 70553 , 70555 ,
70107 Version A, 70107 Version B

Use With

70058 , 71851 , 73838