

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0738380004**
Status: **Active**
Overview: SL Modular Connectors
Description: 2.54mm SL Crimp Housing, Single Row, Version N, TPA with Positive Latch, 4 Circuits, Natural

Documents:

[3D Model](#) [Packaging Specification PK-70873-0540 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-73838-005-001 \(PDF\)](#)

General

Product Family	Crimp Housings
Series	<u>73838</u>
Application	Signal, Wire-to-Board, Wire-to-Wire
Comments	Terminal Position Assurance (TPA) Piece
Overview	<u>SL Modular Connectors</u>
Product Name	SL
UPC	800754789479

Physical

Circuits (maximum)	4
Color - Resin	Natural
Gender	Receptacle
Glow-Wire Capable	No
Material - Resin	Polyester Alloy
Net Weight	0.090/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.54mm
Stackable	No
Temperature Range - Operating	-40° to +105°C


Solder Process Data

Lead-free Process Capability	N/A
------------------------------	-----

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-70873-0540
Product Specification	PS-73838-005-001
Sales Drawing	SD-73838-004

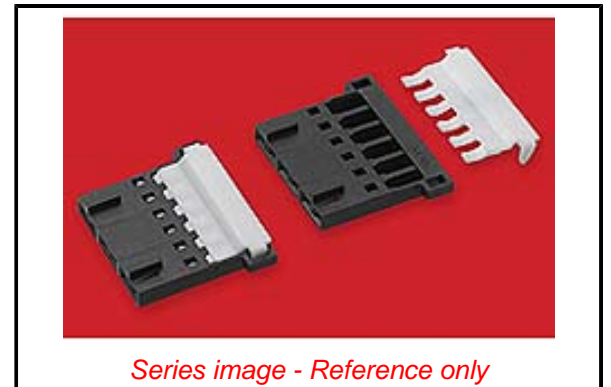

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per
-ED/01/2018 (15
January 2018)

Halogen-Free

Status

Not Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

Search Parts in this Series

73838 Series

Mates With

70018 , 70543 , 70545 , 70553 , 70555 ,
70107 Version A, 70107 Version B

Use With

70058 , 71851 , 73838