

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0887689800](#)
Status: **Active**
Overview: [High Definition Multimedia Interface \(HDMI\)* Products](#)
Description: [HDMI*-to-HDMI* Cable Assembly, 28 AWG, 1.0m Length](#)

Documents:

[Drawing \(PDF\)](#) [Packaging Specification PK-88768-003 \(PDF\)](#)
[Product Specification PS-88768-002-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Cable Assemblies
Series	88768
Assembly Configuration	Dual Ended Connectors
Connector to Connector	HDMI-to-HDMI
Overview	High Definition Multimedia Interface (HDMI)* Products
Product Name	HDMI
UPC	756054858431

Physical

Cable Length	1.0m
Circuits (Loaded)	19
Color - Resin	Natural
Gender	Male-Male
Lock to Mating Part	Yes
Material - Metal	High Performance Alloy (HPA)
Material - Plating Mating	Gold
Material - Plating Termination	Tin
Material - Resin	High Temperature Thermoplastic, Low Density Polyethylene
Net Weight	80.500/g
Packaging Type	Bag
Pitch - Mating Interface	1.00mm
Plating min - Mating	0.813µm
Plating min - Termination	1.270µm
Single Ended	No
Termination Interface: Style	Through Hole
Wire Insulation Diameter	N/A
Wire Size AWG	28
Wire/Cable Type	Round


Electrical

Current - Maximum per Contact	0.5A
Impedance	100Ω
Shielded	Yes
Voltage - Maximum	40V

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-88768-003
Product Specification	PS-88768-002-001
Sales Drawing	SD-88768-9800, SD-887689800

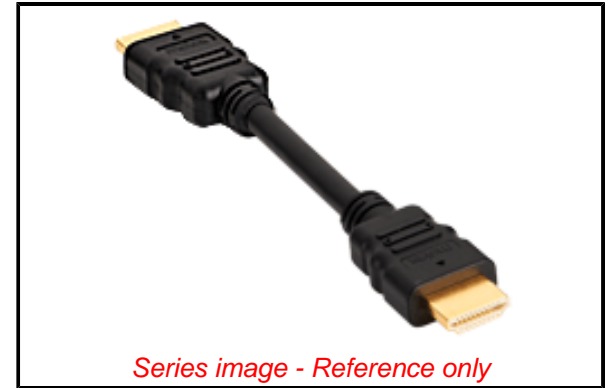

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Not Contained Per
-ED/01/2018 (15
January 2018)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Compliant

Not Contained

Search Parts in this Series

[88768 Series](#)