

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0901230102

Status:


Active

Overview:

C-Grid III Interconnects

Description:

2.54mm Pitch C-Grid III Modular Crimp Housing Single Row, 2 Polarizing Buttons, 2 Circuits, Black

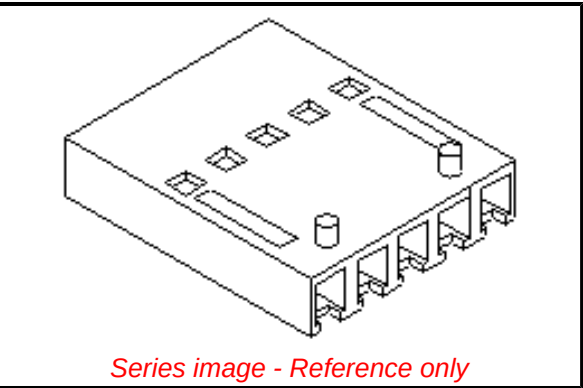

Documents:

3D Model

Drawing (PDF)

Packaging Specification PK-90123-0001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification		
UL		E29179
General		
Product Family		Crimp Housings
Series		90123
Application		Signal, Wire-to-Board
Comments		2 Polarizing Buttons
Overview		C-Grid III Interconnects
Product Name		C-Grid III
UPC		800753707351
Physical		
Circuits (maximum)		2
Color - Resin		Black
Flammability		94V-1
Gender		Receptacle
Glow-Wire Capable		No
Material - Resin		PPO
Net Weight		0.113/g
Number of Rows		1
Packaging Type		Bag
Panel Mount		No
Pitch - Mating Interface		2.54mm
Stackable		Yes
Temperature Range - Operating		-55° to +105°C
Solder Process Data		
Duration at Max. Process Temperature (seconds)		002
Lead-freeProcess Capability		N/A
Max. Cycles at Max. Process Temperature		001
Process Temperature max. C		120
Material Info		
Reference - Drawing Numbers		
Packaging Specification		PK-90123-0001
Sales Drawing		SD-90123

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -

ED/61/2018 (27 June

2018)

Halogen-Free

Status

Low-Halogen

Need more information on product

environmental compliance?

Email productcompliance@molex.com

Please visit the [Contact Us](#) section for any

non-product compliance questions.

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

90123 Series

Mates With

C-Grid III Header 90120 , 90121 , C-Grid III

Header 90136

Use With

C-Grid III Crimp Terminal 90119

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION