

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0923151425](#)
Status: **Active**
Overview: [Picoflex Ribbon-Cable Connectors](#)
Description: Picoflex PF-50 IDT-to-IDT, 14 Circuits, 0.25m Length

Documents:
[3D Model](#) [Product Specification PS-99020-0011-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)


General
Product Family Cable Assemblies
Series [92315](#)
Application Tooling Part Link [62100-6000](#)
Application Tooling Part Link [62100-6010](#)
Assembly Configuration Dual Ended Connectors
Connector to Connector Picoflex IDT-to-IDT
Overview [Picoflex Ribbon-Cable Connectors](#)
Product Name Picoflex
UPC 800754779715

Physical
Cable Length 0.25m
Circuits (Loaded) 14
Color - Resin Natural
Gender Female-Female
Lock to Mating Part None
Material - Metal Phosphor Bronze
Material - Plating Mating Tin
Material - Plating Termination Tin
Material - Resin Polyester
Net Weight 7.620/g
Packaging Type Bag
Pitch - Mating Interface 1.27mm
Plating min - Mating 2.032µm
Plating min - Termination 2.032µm
Single Ended No
Termination Interface: Style IDT or Pierce
Waterproof / Dustproof No
Wire Insulation Diameter N/A
Wire Size AWG 28
Wire/Cable Type PVC, Ribbon Cable

Electrical
Current - Maximum per Contact 1.2A
Shielded No
Voltage - Maximum 250V

Material Info

Reference - Drawing Numbers
Product Specification PS-99020-0011-001
Sales Drawing SD-92315-001

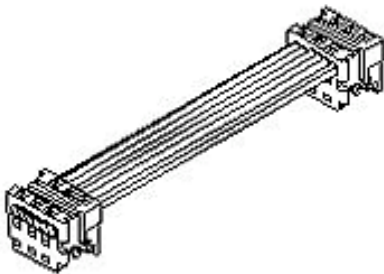

Series image - Reference only

EU ELV
Not Relevant

EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - ED/61/2018 (27 June 2018)	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[92315](#) Series

Mates With
Picoflex PF-50 Header [90325](#) , [90800](#) , [90779](#) , [90715](#) , [90814](#)