


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0009507041](#)
Status: **Active**
Overview: [KK® Interconnect System - Molex](#)
Description: [KK 3.96mm Crimp Terminal Housing, 4 Circuits, Natural](#)

Documents:
[3D Model](#)
[Drawing \(PDF\)](#)
[Product Specification PS-08-50-001 \(PDF\)](#)
[Packaging Specification PK-2139-001-001 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification	
CSA	LR19980
UL	E29179
General	
Product Family	Crimp Housings
Series	2139
Application	Power, Wire-to-Board
Overview	KK® Interconnect System - Molex
Product Name	KK 396
UPC	800753531505
Physical	
Circuits (maximum)	4
Color - Resin	Natural
Flammability	94V-2
Gender	Receptacle
Glow-Wire Capable	No
Material - Resin	Nylon
Net Weight	1.024/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	3.96mm
Temperature Range - Operating	See Product Specification
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Engineering Number	2139-4C
Reference - Drawing Numbers	
Packaging Specification	PK-2139-001-001
Product Specification	PS-08-50-001
Sales Drawing	SD-2139

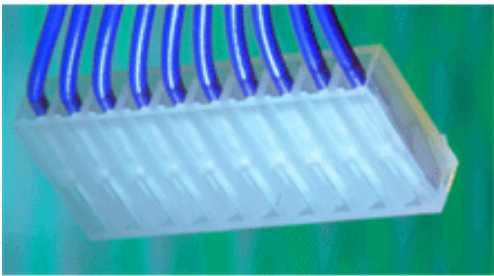

Series image - Reference only

EU ELV Not Relevant	
EU RoHS Compliant REACH SVHC Not Contained Per - ED/61/2018 (27 June 2018) Halogen-Free Status Low-Halogen For more information, please visit Contact US	China RoHS China ROHS ELV RoHS Phthalates
Green Image Not Relevant Not Contained	

Search Parts in this Series
[2139](#) Series

Mates With
KK 396 Headers: [41771](#) , [41772](#) , [41791](#) ,
[41792](#) , [42491](#) , [42492](#) , KK 396 Breakaway
Headers: [41661](#) , [41662](#) , [41671](#) , [41672](#)

Use With
[2478](#) Crimp Terminals for 18-24 AWG, [2578](#)
Crimp Terminals for 22-26 AWG

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION